

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Contact carrier, Ethernet CAT5 (IEC 11801:2002), 8-position, Socket, straight, M12, coding: Y, PCB mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239020

Your advantages

- Reduced mounting costs thanks to two-piece device connector
- Packaging available for automated pick and place assembly
- All common pin assignments and codings available
- Easy device integration thanks to mechanical port screw connections with threaded attachment, press-in contour or direct integration in the front plate

Commercial data

Item number	1413445
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	ABQ
Product key	ABQAGT
GTIN	4046356999076
Weight per piece (including packing)	7.479 g
Weight per piece (excluding packing)	7.479 g
Customs tariff number	85366930
Country of origin	DE

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

Technical data

Notes

Notes on operation	The electrical and mechanical data specified assume that the connector pair is correctly locked and mounted. If the connector is unlocked and if there is a danger of contamination, the connector must be sealed using a protective cap > IP54. Influences arising from litz wires, cables or PCB assembly must also be taken into consideration.
--------------------	----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Product properties

Product type	Contact insert
Application	Hybrid
Sensor type	Ethernet
Number of positions	8
Seal present	no
Shielded	yes
Coding	Y
Thread type	M12

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Electrical properties

Contact resistance	≤ 3 mΩ
Insulation resistance	100 MΩ
Nominal voltage U _N	48 V AC (Power and data)
	50 V DC (Power and data)
Nominal current I _N	0.5 A (Data)
	6 A (Power)
Transmission medium	Copper
Transmission characteristics (category)	CAT5 (IEC 11801:2002)

Connection data

Connection method	THR solder connection
-------------------	-----------------------

Interfaces

Signal type/category	Ethernet CAT5 (IEC 11801:2002)
----------------------	--------------------------------

Dimensions

Length of the solder pin	2.3 mm
	2.3 mm

Material specifications

Flammability rating according to UL 94	V0
----------------------------------------	----

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

Contact material	CuZn
Contact surface material	Au
Contact carrier material	PPA

Connector

Connection 1

Head design	Socket
Head cable outlet	straight
Head thread type	M12
Coding	Y

Cable/line

Signal type/category	Ethernet CAT5 (IEC 11801:2002)
----------------------	--------------------------------

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	-------

Environmental and real-life conditions

Ambient conditions

Degree of protection (when plugged in)	IP67 (correctly plugged in and locked)
Degree of protection	IP67 (correctly plugged in and locked)
	IP67, when plugged in
Ambient temperature (operation)	-40 °C ... 90 °C
UL Type Rating	Type 4 (indoor use only)

Mounting

Mounting type	PCB mounting
---------------	--------------

Packaging specifications


Type of packaging	Belt
Delivery state	with assembly pad

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier

1413445

<https://www.phoenixcontact.com/in/products/1413445>

Drawings

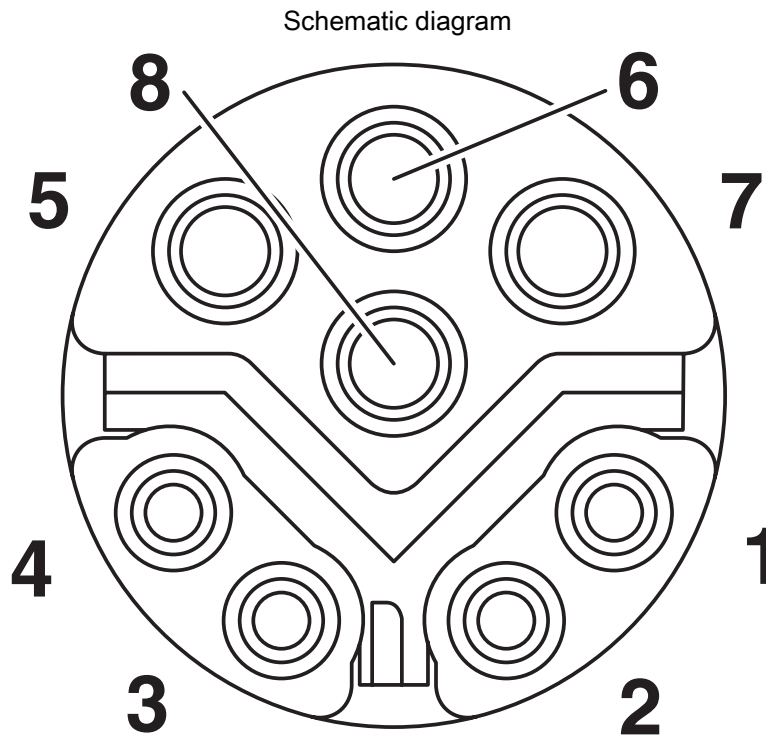

Pin assignment M12 connector, 8-pos., view socket side

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445
<https://www.phoenixcontact.com/in/products/1413445>

Classifications

ECLASS

ECLASS-11.0	27440223
ECLASS-12.0	27440116
ECLASS-13.0	27440223

ETIM

ETIM 9.0	EC003557
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	bada1269-e3d9-40c4-a3ba-51cd9efe555b

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

Accessories

SACC-CI-M12FSY-8CON-L180THR SP - Sample set

1420414

<https://www.phoenixcontact.com/in/products/1420414>



Sample set, 8-position, Socket, straight, M12, coding: Y, Rear mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239310

SACC-M12-SCO NUT - Housing screw connection

1552243

<https://www.phoenixcontact.com/in/products/1552243>



Housing screw connection, Socket, M12-SPEEDCON, Front mounting, M12 x 1, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237399

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-DSIV-M12-NUT - Housing screw connection

1416144

<https://www.phoenixcontact.com/in/products/1416144>



Housing screw connection, Socket, M12, Front mounting, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239107

SACC-M12-SCO NUT L 90 - Housing screw connection

1432460

<https://www.phoenixcontact.com/in/products/1432460>



Housing screw connection, M12-SPEEDCON, Front mounting, M12 x 1, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237409

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-BP-F-M12/M15-6-THR - Housing screw connection

1414004

<https://www.phoenixcontact.com/in/products/1414004>



Housing screw connection, Socket, M12, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239056

SACC-BP-F-M12/M15-7-THR - Housing screw connection

1414003

<https://www.phoenixcontact.com/in/products/1414003>



Housing screw connection, Socket, M12, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239055

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-BP-F-M12/M15-6-THR SCO - Housing screw connection

1414020

<https://www.phoenixcontact.com/in/products/1414020>



Housing screw connection, Socket, M12-SPEEDCON, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239057

SACC-BP-F-M12/M15-7-THR SCO - Housing screw connection

1414005

<https://www.phoenixcontact.com/in/products/1414005>



Housing screw connection, Socket, M12-SPEEDCON, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237398

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-BP-F-M12/THR-1,0/1,8-9TIP - Housing screw connection

1419630

<https://www.phoenixcontact.com/in/products/1419630>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 1.0 mm ... 1.8 mm thick front plates.

SACC-BP-F-M12/THR-1,7/2,5-9TIP - Housing screw connection

1419631

<https://www.phoenixcontact.com/in/products/1419631>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 1.7 mm ... 2.5 mm thick front plates.

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-BP-F-M12/THR-2,4/3,2-9TIP - Housing screw connection

1419633

<https://www.phoenixcontact.com/in/products/1419633>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 2.4 mm ... 3.2 mm thick front plates.

SACC-BP-F-M12/THR-3,1/3,9-9TIP - Housing screw connection

1419634

<https://www.phoenixcontact.com/in/products/1419634>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 3.1 mm ... 3.9 mm thick front plates.

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-M12 NUT PRESS - Housing screw connection

1437889

<https://www.phoenixcontact.com/in/products/1437889>



Housing screw connection, Socket, M12, Front mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237410

SACC-DSIV-M12-NUT-9 THR - Housing screw connection

1417989

<https://www.phoenixcontact.com/in/products/1417989>



Housing screw connection, Front mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239181

SACC-CI-M12FSY-8CON-L180 TOR32 - Contact carrier



1413445

<https://www.phoenixcontact.com/in/products/1413445>

SACC-BP-F-M12-THR PP - Housing screw connection

1027662

<https://www.phoenixcontact.com/in/products/1027662>



Housing screw connection, Socket, M12-Push-pull external locking, Rear mounting, M16, THR- und Wellenlötkontakte, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

SACC-FP-F-M12-THR PP - Housing screw connection

1027678

<https://www.phoenixcontact.com/in/products/1027678>



Housing screw connection, Socket, M12-Push-pull external locking, Front mounting, M14 x 1, THR- und Wellenlötkontakte, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in