

Datasheet

RS PRO LED Twin Weatherproof – 4ft Emergency


Stock No: 2105498



Model:	4' 55W 600mm Polycarbonate Emergency Weatherproof Twin IP65
Length	1200mm
Width	96mm
Height	83mm
Weight	12.48kg

Features & Benefits:

- Suitable for industrial and commercial applications
- Energy savings of up to 50%, compared to fluorescent fittings
- ENEC Approved Driver
- Wide Voltage range (100-240V), with built in low voltage protection device
- Operating temp of 0°C to +50°C
- 3 hours emergency duration (250Lm)
- Improved install design. 2-part fitting allows for quicker installation
- Supplied with tamper proof, stainless steel clips
- Compatible with besa box mounting.

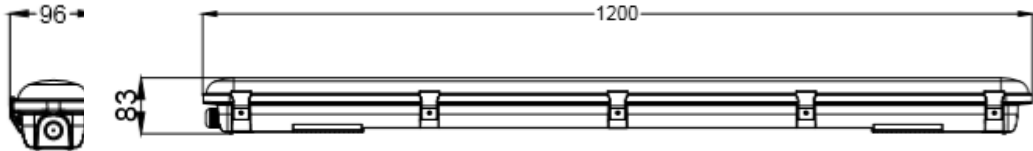

Model:	4' 55W 600mm Polycarbonate Emergency Weatherproof Twin IP65
Operating Wattage	55W
Operating Voltage	100-240V 50-60Hz
Power Factor	≥0.9
Colour Temperature	6500K
Luminous Flux	6600Lm
Luminous Efficiency	120Lm/W
CRI	≥80
Lifespan	50,000 Hrs
IP rating	IP65
IK Rating	IK08