

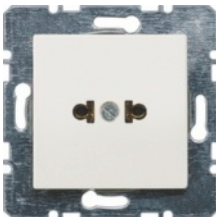




International plug-and-socket devices

Selection and ordering data

Version	DT	Order No.	Price per PU	PU (UNIT, SET, M)	PS*/ P. unit	PG
General information <ul style="list-style-type: none"> • With screw and claw fixing • Screw terminals • Degree of protection IP20 • Size of cover plates: 55 mm x 55 mm 						
Note		Section	Page			
For extension claws, see ...		<i>Functions / Switching/ Pushbutton Control/ Dimming / Accessories and spare parts</i>	10/19			
 Socket outlets with grounding pin and increased touch protection <ul style="list-style-type: none"> • 16 A, 250 V AC • 2-pole according to CEE7 • French/Belgian standard • With anti-slip terminals for 4 x 2.5 mm² 						
Versions						
• Titanium white (similar to RAL 9010)		A	5UB1 918	1	1/10 units	021
• Electrical white (RAL 1013)		A	5UB1 908	1	1/10 units	021
• Aluminum metallic (similar to RAL 9006)		A	5UB1 938	1	1/10 units	021
• Carbon metallic (similar to RAL 7016)		A	5UB1 928	1	1/10 units	021
5UB1 918						
 Socket outlets with grounding pin <ul style="list-style-type: none"> • 16 A, 250 V AC • 2-pole according to CEE7 • French/Belgian standard • With anti-slip terminals for 4 x 2.5 mm² 						
Versions						
• Titanium white (similar to RAL 9010)		A	5UB1 350	1	1/10 units	021
• Electrical white (RAL 1013)		A	5UB1 348	1	1/10 units	021
5UB1 350						
 Socket outlets, according to American standard C 73 <ul style="list-style-type: none"> • 15 A, 125 V AC • 51 mm x 51 mm 						
Versions						
• Titanium white (similar to RAL 9010)		A	5UB1 307	1	1/10 units	021
• Electrical white (RAL 1013)		D	5UB1 303	1	1/10 units	021
Note		Section	Page			
Intermediate frames must be ordered separately, see ...		<i>Design / DELTA line / Frames</i>	2/6			
		<i>Design / DELTA vita / Frames</i>	2/5			
5UB1 307						
 NEMA socket outlets <ul style="list-style-type: none"> • 2-pole (2P + E) • NEMA 5-20R • 20 A, 125 V AC • For 58 series mounting boxes • For screw fixing only • Titanium white (similar to RAL 9010) 						
5UB1 534						
 NEMA socket outlets with hinged lid <ul style="list-style-type: none"> • 2-pole (2P + E) • NEMA 5-20R • 20 A, 125 V AC • For 58 series mounting boxes • For screw fixing only • Titanium white (similar to RAL 9010) 						
5UB1 535						