



@ansell_lighting



ansellighting



Ansell Lighting







ansell_lighting

Endurance UGR<19 1200x600

Endurance TP(a) UGR<19 1200x600 Panel

Code: AERMLED3/120/DL

Category	Commercial Panels
Application	Ancillary, Commercial, Education, Healthcare, Retail
Specification	Performance

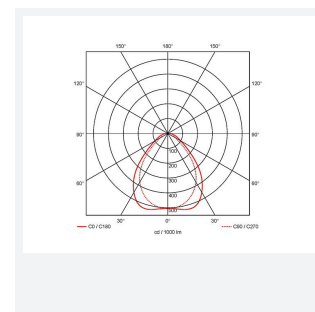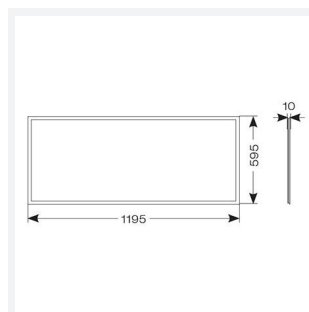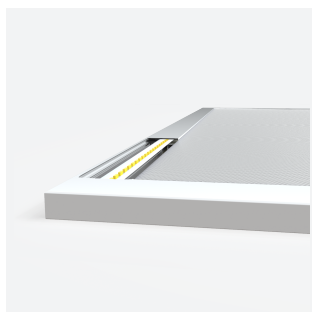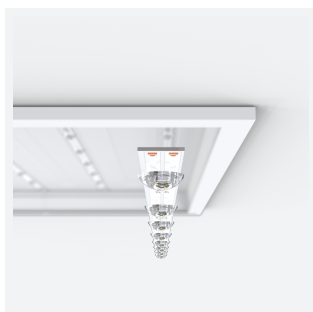

PRODUCT FEATURES

- Edge lit LED panel suitable for education, commercial and ancillary area applications
- Cool white, warm white and daylight options
- Surface mounting frame option
- Switch Dim, DALI and 0-10V dimming capability using the multi dimmable driver accessories ADDIM/60/MC
- UGR<19 (unified glare rating) compliant luminaire assisting to eliminate glare for visual comfort
- White anodised aluminium frame for visual compatibility with ceiling grid
- TP(a) as standard
- Compatible with either the self-test panel pod or the sensor pod

GENERAL INFORMATION

Wattage	60W
Lumens Delivered	5400lm
Lm/W	90lm/W
Beam Angle	80
CRI	80
CCT	6000K
Input	220-240V
Operating Temp	-20? to 40?
SDCM	6
UGR	17
Product Weight without Packaging	4.843 kg

TECHNICAL INFORMATION

Light Source	LED
Colour / Finish	White
IP Rating	IP44
Class Protection	2
Internal / External	Internal
Surface / Recessed / Suspended	Recessed, Surface
Lumen Depreciation	L80 76,000h
Warranty (Years)	5
CE Mark	Yes
Height	10 mm
Accessories	AERMLED/120/SMF, APRK/120

