



zQSFP+/QSFP28

TE Internal #: 2333393-5
QSFP28 Cable Assembly, 16 Positions, 2 m [6.56 ft], 25 Gb/s, Black
Cable, Shielded, 30 AWG, .051 mm² Wire, QSFP28 Plug End A,
QSFP28 Plug End B, CL2

[View on TE.com >](#)

Cable Assemblies > Copper Cable Assemblies > Pluggable I/O Cable Assemblies > QSFP28 to QSFP28 Cable Assembly: 30 AWG



Cable Assembly Type: **QSFP28**
Number of Positions: **16**
Cable Assembly Length: **2 m [6.56 ft]**
Data Rate: **25 Gb/s**
Cable Color: **Black**

[All QSFP28 to QSFP28 Cable Assembly: 30 AWG \(6\)](#)

Features

Product Type Features

Cable Assembly Category	High Speed, Industry Standard
Cable Assembly Type	QSFP28
Cable Style	Madison TurboTwin - Round Jacketed
Cable Assembly (End A)	QSFP28 Plug
Cable Assembly (End B)	QSFP28 Plug

Configuration Features

Number of Positions	16
Number of Pairs	8
Number of Signal Positions	16

Electrical Characteristics

Impedance	100 Ω
-----------	-------

Signal Characteristics

--	--



Data Rate	25 Gb/s
-----------	---------

Body Features

Cable Color	Black
Equalized	No
Cable Flammability Rating	CL2

Dimensions

Wire Size	.051 mm²
Outside Cable Diameter	6.2 mm[.244 in]

Operation/Application

Shielded	Yes
Halogen Free	No

Other

Cable Assembly Configuration	Double Ended
Cable Assembly Length	2 m[6.56 ft]

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides



on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 2326093-1
CAGE ASSY, QSFP28 1X1, SPRING, LP

TE Part # 2227249-1
1x4 Cage Assy Bhnd Bzl QSFP28

TE Part # 2304807-2
CAGE ASSY, QSFP28 1X1, SPRING, HS

TE Part # 2316805-1
CAGE ASSY, QSFP28 1X1, GASKET, HS

TE Part # 2170752-5
CAGE ASSEMBLY, QSFP28 1X1, GASKET

TE Part # 2170708-6
CAGE ASSY, 1X6, QSFP28, SPRING, HS, LP

TE Part # 2170826-5
CAGE ASSEMBLY, 1X2, QSFP28, SPRING,HS,LP

TE Part # 2309399-1
QSFP28, 1X3, CAGE ASSEMBLY, SPRING, HS

TE Part # 2170706-4
CAGE ASSEMBLY, 1X6, QSFP28, SPRING

TE Part # 2170706-5
CAGE ASSEMBLY, 1X6, QSFP28, SPRING

TE Part # 2294662-2
CAGE ASSY,1X4, QSFP28,SPRING, HS, DUAL LP

TE Part # 2306205-2
CAGE ASSY, QSFP28 1X1, GASKET, CZD HS

TE Part # 1-2170708-1
CAGE ASSY, 1X6, QSFP28, SPRING, CSHS, LP

TE Part # 1551910-2
Housing for zQSFP+, 38 positions

 
TE Part # 2170773-7
CAGE ASSY, QSFP28 1X1, SINGLE LP

TE Part # 4-2170814-6
QSFP28, 1X2, CAGE ASSY, GASKET, HS, LP





TE Part # 2170814-6
QSFP28, 1X2, CAGE ASSY, GASKET, HS, LP



TE Part # 2306820-1
QSFP28, 1X2, CAGE ASSY, SPRING, HS, C LP




TE Part # 1-2170704-1
CAGE ASSY, QSFP28 1X1, SPRING, HS




TE Part # 5-2170703-4
CAGE ASSEMBLY, QSFP28 1X1, SPRING


Also in the Series | zQSFP+/QSFP28

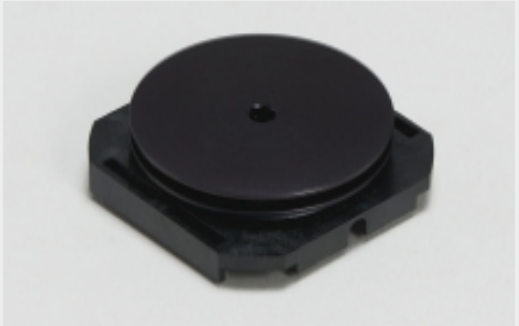

Heat Sinks(7)

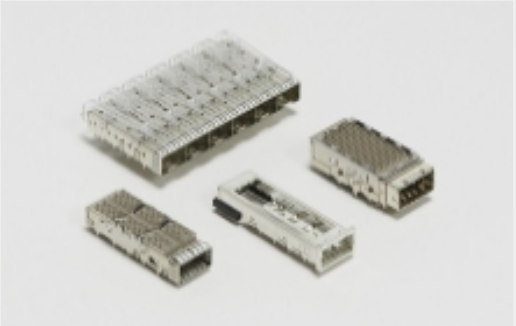

Pluggable IO Connectors & Cages(424)

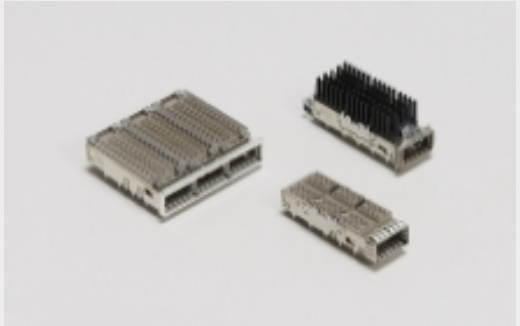

QSFP, QSFP+ & zQSPF+(424)

Customers Also Bought



TE Part #2336313-4
QSFP 25GIG 32AWG 2 METER




TE Part #CAT-Q17-N490325
QSFP56 to QSFP56 Cable Assembly: 30 AWG




TE Part #DP86-005D
5 PSID MV DIFFERENTIAL PRESSURE SENSOR



TE Part #2333393-7
QSFP 25GIG 30AWG 3 METER

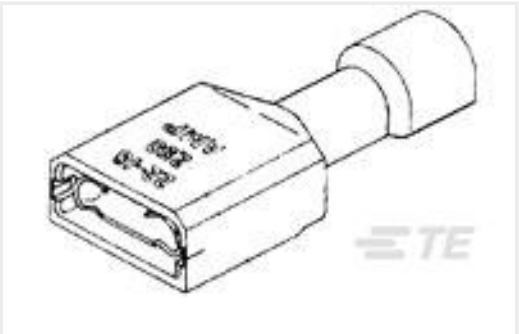


TE Part #3-350819-2
ULTRA-FAST 250 ASY REC 16-14 AWG TPBR

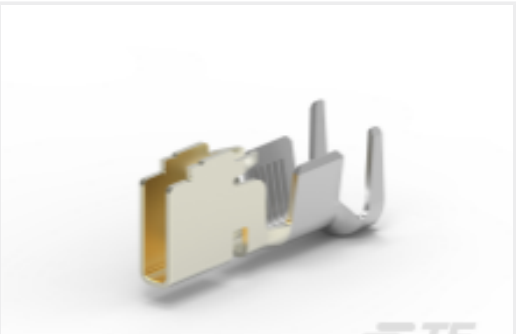


TE Part #1-1600960-7
CONT 8-10 AWG PWR, MFBL PLATE



TE Part #30997
DG R 22-16 COMM 22-18 MIL10

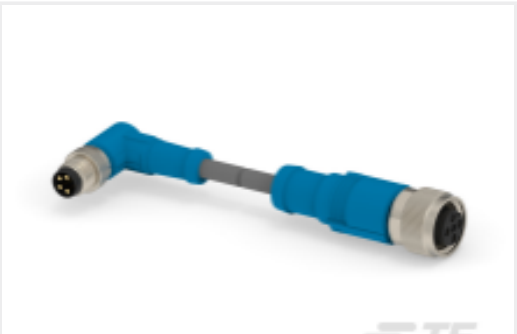

 TE Part #T4052227004-001
RPC-M8-4MR-0.5-M12-4FS-PUR



TE Part #2428274-3
QSFP28-QSFP28,AOC 3m,SonyVCSEL, BER 1E-12



Documents

Product Drawings

QSFP 25GIG 30AWG 2 METER

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2333393-5_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2333393-5_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2333393-5_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English

Product Specification

English