

Fellowes

Ergonomic Solutions



Breyta™

Ergonomic Vertical Mouse

Features:

- Avoid wrist strain whilst mousing. Designed with a 60° angle to encourage a more natural operating 'handshake' position to avoid tension in the hand and forearm.
- 2 in 1 connectivity. Bluetooth® wireless technology or wired connectivity for flexibility.
- Precision optical sensor and scroll wheel aids fast, accurate tracking and document scrolling (800, 1200, 1600 dpi).
- Plastic housing and buttons made from 100% post-consumer recycled content.
- Long lasting rechargeable battery with up to 4 months of average use. Fully charges in approx. 2 hours.
- Tested by FIRA International Ltd to comply with the ergonomic requirements set out in the European Health and Safety Legislation: EN ISO 9241-5.



Specification:

Colour	Black
Code	100143579
Hand Measurement	16.5 - 18.5 cm
Size	Medium
Right or Left Hand Use	Right-Handed
DPI	800, 1200, 1600
Compatibility	Compatible with the latest versions of Windows and Mac Os
Bluetooth® Wireless Technology	✓
Wired	✓
Max wireless range	10m
Battery	Li-on rechargeable battery, 3.7V 500mAh
Battery Weight	9.2 g
Battery Usage Time	Up to 4 months average usage
Charging Time	Approx. 2 hours
Deep Sleep Mode	Activates after 30 minutes of inactivity
Features	Plastic housing and buttons made from 100% post-consumer recycled content
Number of buttons	3
Product Dimensions (H x W x D)	7.50 x 8.30 x 10.45 cm
Product Weight	0.12 kg
Retail Carton Dimensions (H x W x D)	14.20 x 11.50 x 8.50 cm
Retail Carton Weight	0.27 kg
Outer Carton Dimensions (H x W x D)	14.90 x 23.80 x 18.00 cm
Outer Carton Weight	1.23 kg
Retail Barcode (UPC)	043859814107
Outer Carton Barcode (SCS)	10043859814104
Quantity per Outer Carton	4
Country of Origin	China
Warranty	5-year limited

RELIEVE WRIST STRAIN

Work in comfort. Vertical design helps reduce twisting and tension whilst mousing.



PRODUCT INCLUDES RECYCLED CONTENT

CERTIFIED ERGONOMIC
INDEPENDENTLY ASSESSED TO COMPLY WITH EN ISO 9241-5

ERGONOMIC VERTICAL DESIGN

ENCOURAGES A MORE NATURAL, RELAXED "HANDSHAKE" POSITION



60° ANGLE

2 IN 1 CONNECTIVITY

BLUETOOTH® WIRELESS TECHNOLOGY, WIRED CONNECTIVITY



Bluetooth®

Compatible with the latest versions of Windows and Mac Os

ENHANCE PERFORMANCE




PRECISION SCROLL WHEEL WITH AUTO SCROLL*
*Windows only

LEFT CLICK

RIGHT CLICK

3 SPEED SETTINGS
800, 1200, 1600 dpi

LONG LASTING BATTERY LIFE

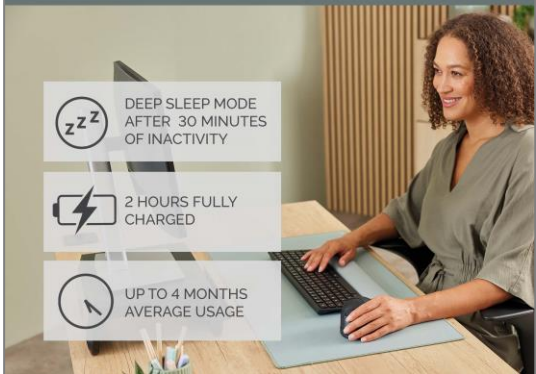

DEEP SLEEP MODE AFTER 30 MINUTES OF INACTIVITY

2 HOURS FULLY CHARGED

UP TO 4 MONTHS AVERAGE USAGE

ENVIRONMENTALLY CONCIIOUS



100% RECYCLED CONTENT

Plastic housing and buttons made from 100% post-consumer recycled content

Fellowes 5 YEAR WARRANTY

Ergonomic Working:



ZONE 2

AVOID WRIST PRESSURE

Support your wrists.



Keep forearms parallel with the top of your desk and wrists in a neutral posture.

Why use a Vertical Mouse

- Vertical mice aim to eliminate forearm twisting and encourage a more natural, relaxed working hand posture – 'Handshake position'
- Movement is transferred into the more powerful shoulder muscles to reduce strain on the wrist muscles, helping prevent repetitive strain injury (RSI) and carpal tunnel syndrome (CTS).
- Pressure is transferred to the little finger, avoiding compression of the soft tissue of the wrist.

How to use a Vertical Mouse

1. **Position:** Ensure your forearms are parallel with the desk and wrists are in a neutral position
2. **Distance:** Ensure the mouse isn't positioned too far away from your body to avoid pain in the mousing arm's shoulder.

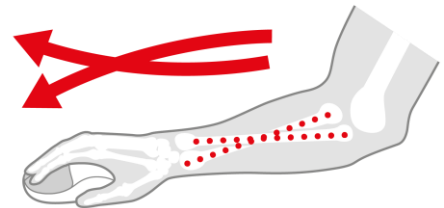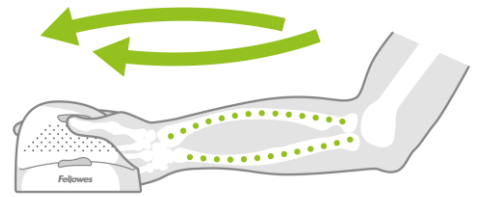

Certifications:

EN ISO 9241-5 1999 Ergonomic requirements for office work with visual display terminals (VDT's): part 5: 1999, workstation layout and postural requirements.

SCS Global Services Indoor Advantage™ Gold: Indoor Air Quality Certified to SCS-105 v4.2



Aftercare:

Recycling: Please check with your local recycling facility on how to recycle your product correctly when no longer required. For more information visit [Recycle Your Electricals - WEEE Recycling](#)

Cleaning: Wipe over with a damp microfibre cloth. Do not use any cleaning solutions.

Handling & Storage: Read and follow all instructions and warnings before use. This product is intended for indoor use only.

Environmental:


Product	Product Material Breakdown		Product Recycled Content		
	Weight (g)	Weight (%)	Pre-Consumer Recycled Content (g)	Post Consumer Recycled Content (g)	Total Recycled Content (%)
Acrylonitrile Butadiene Styrene (ABS)	68.9	57%	0	68.9	100%
Polyvinyl Chloride (PVC)	18.6	15%	-	-	-
Electronics	17.6	15%	-	-	-
Li-on battery	9.2	8%	-	-	-
Steel	4.6	4%	-	-	-
Silicone	1.2	1%	-	-	-
Polycarbonate (PC)	0.9	<1%	0	0.9	100%
Total	121.0	100%	0	69.8	58%

Packaging	Product Material Breakdown		Product Recycled Content		
	Weight (g)	Weight (%)	Pre-Consumer Recycled Content (g)	Post Consumer Recycled Content (g)	Total Recycled Content (%)
Corrugated Box	81	56%	0	80	99%
Corrugated Placeholders	33	23%	0	33	100%
Cardboard Sleeve	17	12%	0	17	100%
Paper Manuals	13	9%	0	13	100%
Total	144	100%	0	143	100%

Pre-Consumer Recycled Content: Waste material that was created during the process of manufacturing or delivering goods prior to their delivery to consumers.

Post-Consumer Recycled Content: Waste material created by consumers. This material is diverted from landfills and utilized in the production of other commodities.

Recyclability:

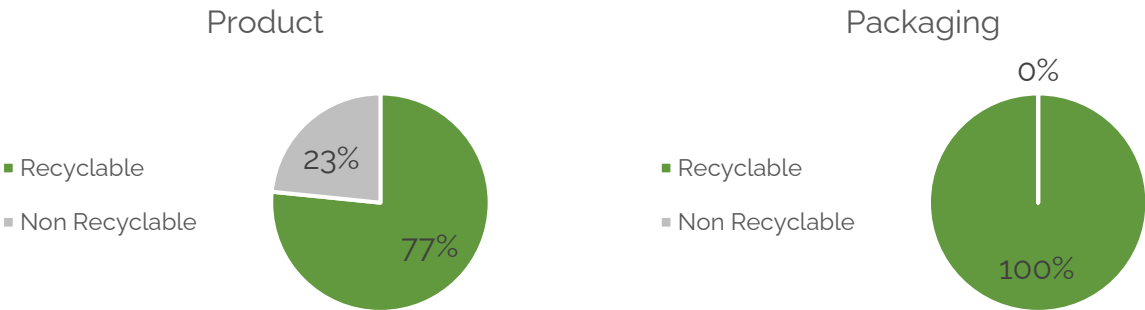

Dimensional Drawings:



MEDIUM

16.5 - 18.5CM
Right-handed



MEASURE FROM TIP OF YOUR MIDDLE
FINGER TO BASE OF YOUR HAND



8.3 cm



10.45 cm