




HEATED TABLE

Technical Specification

Heated Table

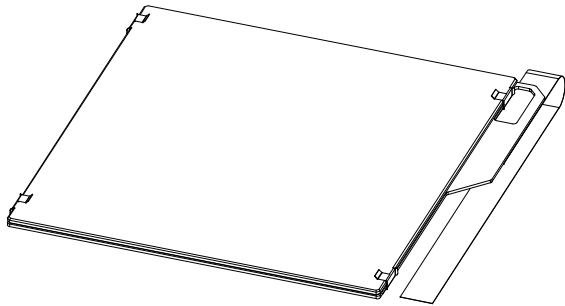

SPECIFICATION

| | |
|----------------|--|
| Construction | 2 mm aluminium base with 4 mm glass surface (Planimax) |
| Max. Temp. | 115 [°C] |
| Power | 140 [W] |
| Work area | 235 x 250 [mm] |
| Mounting | Magnets + lever |
| Bed dimensions | 274 x 252 x 21 [mm] |

