 



Product description

MAIN FEATURES

- › Robust solid aluminum design (RoHS compliant)
- › For round shafts or D-shape
- › Anodized surface, scratch resistant, electrically non-conducting
- › Customized designs and colors on request



K1 METAL KNOBS

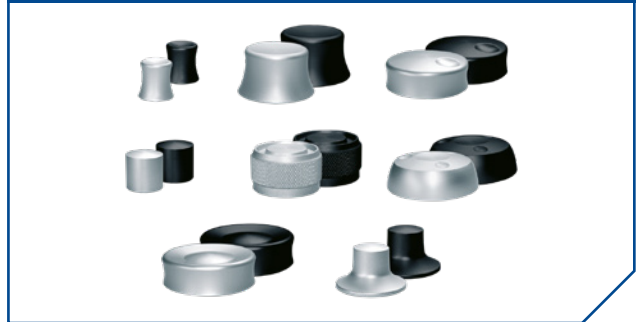

PRODUCT VARIETY


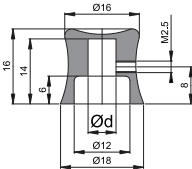

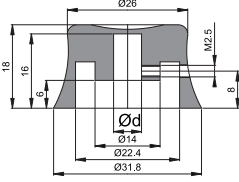

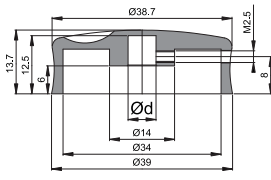
 
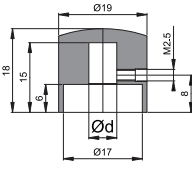

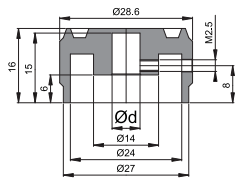

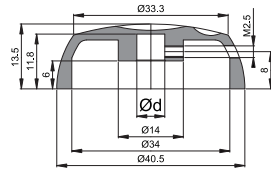

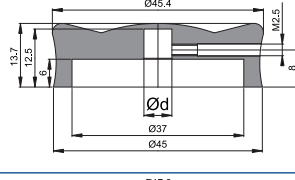

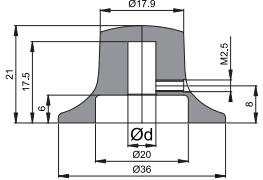
- Knob design: Shape, Shaper, Dimple, Pure, Robot, Space, Cone, Medic
- Shaft diameter (standard): 6 mm
- Anodized surface, silky sheen
- Black or natural color

POSSIBLE CUSTOMIZATIONS

- Knob design
- Shaft diameter 3 mm, 3.18 mm (1/8"), 4 mm, 6.35 mm (1/4")
- Colors: Red, gold, green, light or dark blue
additional colors available on request

Dimensions and ordering information

SHAPE, DIMENSION AND PART NUMBER

SHAPE	SHAFT DIAMETER $\varnothing d \begin{smallmatrix} +0.028 \\ -0.010 \end{smallmatrix}$ stock type*	PART NUMBER	
		SILVER	BLACK
 	3 mm	K1-SH-S30	K1-SH-B30
	3.18 mm (1/8")	K1-SH-S32	K1-SH-B32
	4 mm	K1-SH-S40	K1-SH-B40
	6 mm*	K1-SH-S60	K1-SH-B60
	6.35 mm (1/4")	K1-SH-S64	K1-SH-B64
 	3 mm	K1-SR-S30	K1-SR-B30
	3.18 mm (1/8")	K1-SR-S32	K1-SR-B32
	4 mm	K1-SR-S40	K1-SR-B40
	6 mm*	K1-SR-S60	K1-SR-B60
	6.35 mm (1/4")	K1-SR-S64	K1-SR-B64
 	3 mm	K1-DM-S30	K1-DM-B30
	3.18 mm (1/8")	K1-DM-S32	K1-DM-B32
	4 mm	K1-DM-S40	K1-DM-B40
	6 mm*	K1-DM-S60	K1-DM-B60
	6.35 mm (1/4")	K1-DM-S64	K1-DM-B64
 	3 mm	K1-PR-S30	K1-PR-B30
	3.18 mm (1/8")	K1-PR-S32	K1-PR-B32
	4 mm	K1-PR-S40	K1-PR-B40
	6 mm*	K1-PR-S60	K1-PR-B60
	6.35 mm (1/4")	K1-PR-S64	K1-PR-B64
 	3 mm	K1-RB-S30	K1-RB-B30
	3.18 mm (1/8")	K1-RB-S32	K1-RB-B32
	4 mm	K1-RB-S40	K1-RB-B40
	6 mm*	K1-RB-S60	K1-RB-B60
	6.35 mm (1/4")	K1-RB-S64	K1-RB-B64
 	3 mm	K1-SC-S30	K1-SC-B30
	3.18 mm (1/8")	K1-SC-S32	K1-SC-B32
	4 mm	K1-SC-S40	K1-SC-B40
	6 mm*	K1-SC-S60	K1-SC-B60
	6.35 mm (1/4")	K1-SC-S64	K1-SC-B64
 	3 mm	K1-CN-S30	K1-CN-B30
	3.18 mm (1/8")	K1-CN-S32	K1-CN-B32
	4 mm	K1-CN-S40	K1-CN-B40
	6mm*	K1-CN-S60	K1-CN-B60
	6.35 mm (1/4")	K1-CN-S64	K1-CN-B64
 	3 mm	K1-MD-S30	K1-MD-B30
	3.18 mm (1/8")	K1-MD-S32	K1-MD-B32
	4 mm	K1-MD-S40	K1-MD-B40
	6 mm*	K1-MD-S60	K1-MD-B60
	6.35 mm (1/4")	K1-MD-S64	K1-MD-B64

Tolerances unless otherwise specified: DIN ISO 2768-m

Ordering information

PACKAGING

CONTENT OF STANDARD PACKAGING

- 20 pieces for Shaper, Robot, Space, Dimple, Cone, Medic
- 40 pieces for Shape or Pure
- 1 piece allen key M2.5 x 4 mm per knob
- 1 piece allen key 1.3 mm



20 pieces for Shaper, Robot, Space, Dimple, Cone, Medic



40 pieces for Shape or Pure

ACCESSORIES AND SPARE PARTS

DESCRIPTION	QUANTITY	PART NUMBER
Allen key 1.3 mm	1 piece	K1-HEXKEY
Set screw M2.5 x 4 mm	1 piece	5404-32

Specifications

Mechanical data

Max. tightening torque of set screw 0.2 Nm

Materials

Anodized aluminum

©Copyright 2018 by Elma Electronic AG, CH-8620 Wetzikon. Subject to technical modifications, all data supplied without liability.

Please contact our sales team for more details.

China: +86 21 5866 5908
France: +33 388 56 72 50

Germany: +49 7231 97 34 0
Israel: +972 3 930 50 25

Singapore: +65 6479 8552
Switzerland: +41 44 933 41 11

United Kingdom: +44 1234 838 822
United States: +1 510 656 3400