




ENGLISH

Datasheet

Stock No: 522-531

RS Pro 3 Core Screened SY Control Cable, Polyvinyl Chloride PVC Sheath

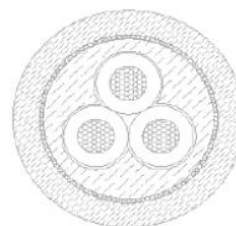

Conductor: Bare Copper
Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$
Insulation: PVC
Insulation Dia. (mm): $2.8 \pm 0.1 \times 3C$
Filler: Chalk
Jacket 1: PVC
Outer Dia. (mm): 6.95 ± 0.2
Braid Shield: Galvanised Steel
Conductor Dia. (mm): 0.24
Conductor Qty: 24 x 3
Pitch(mm):
Coverage: 70%
Jacket: Trans PVC
Outer Dia. (mm): 10.03 ± 0.25

Colour:

The colour of the insulation: Blue , Brown , Yellow/Green

The jacket colour: Transparent

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω /Km) :

<13.7

Min.Insulation DC Resistance at 20°C ($M\Omega * KM$) :

>500

Current Rating : 16 A