


PREVOS1 SAFETY QUICK COUPLINGS - CSI 08

Female thread double port wall
bracket - 2 couplers and drain - ISO
6150 C Profile



Part number	Female thread	Min. operating pressure (bar)	Flow rate at 6.00 bar (l/min) ($\Delta P = 0.60$ bar)	ID passage (mm)	Temperature min/max (°C)
CSI 088103WK	G1/2	2.00 / 12.00	2028.00	8 mm	-15.00 / 70.00
CSI 088104WK	G3/4	2.00 / 12.00	2028.00	8 mm	-15.00 / 70.00

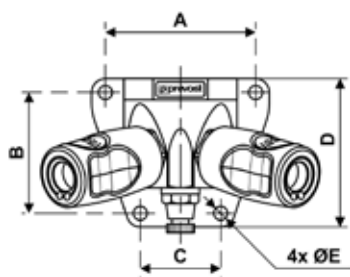

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)	Dim. D (mm)	Dim. E (mm)
CSI 088103WK	71.00	57.00	38.00	70.00	6.50
CSI 088104WK	71.00	57.00	38.00	70.00	6.50