

Datasheet

RS Pro P13.5s Filament Indicator Lamp, Clear, 5.95 V, 500 mA, 15h

RS Stock No: **655-9110**



Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 5.95 V and current rating of 500 mA. The lamp has 15 h life.

Features and Benefits

- Olive shape B3 1/2 - 11 mm glass
- P13.5s prefocus base
- Vacuum




Specifications:

Current Rating	500 mA
Diameter	11 mm
Lamp Base	P13.5s
Lamp Size	B3 1/2
Length	28 mm
Lens Colour	Clear
Life Hours	15 h
Luminosity	39 lm
Voltage Rating	5.95 V

RS Stock No.

6559110

DRAWING - I

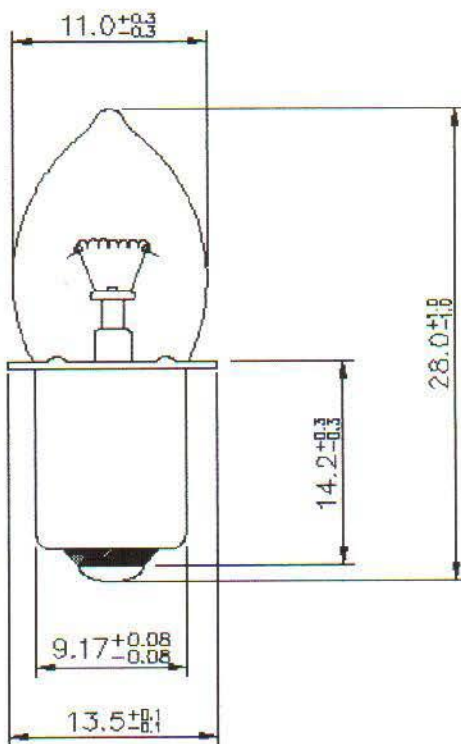

Unit : mm

1. Structure	Bulb Type	B3 1/2
	Bulb Diameter	Ø 11.0Max.
	Length	28.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	5.95V
	Amperage	500mA± 10%
	Luminous Flux	39Lm±20%
	Life Hours	15Hrs