


# Geberit Mapress Copper elbow adaptor union 90° with female thread



Example image

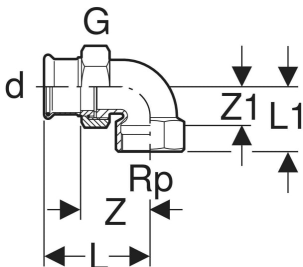

## APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)
- For negative pressure

- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

## CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Union nut made of brass
- Seal ring made of CIIR, black

## TECHNICAL DATA

|                                          |                               |
|------------------------------------------|-------------------------------|
| Medium temperature with flat gasket EPDM | 0–100 °C                      |
| Product material                         | Gunmetal / lead-free gunmetal |

| Art. no. | DN      | d <sub>ø</sub> mm | Rp " | G "   | Product material   | arc ° | L cm | L1 cm | Z cm | Z1 cm |
|----------|---------|-------------------|------|-------|--------------------|-------|------|-------|------|-------|
| 65382    | 12 / 15 | 15                | 1/2  | 3/4   | Lead-free gunmetal | 90    | 5.7  | 3.2   | 3.7  | 1.9   |
| 65392    | 15      | 18                | 1/2  | 3/4   | Lead-free gunmetal | 90    | 5.7  | 3.2   | 3.7  | 1.9   |
| 65384    | 20      | 22                | 3/4  | 1     | Gunmetal           | 90    | 6.4  | 3.6   | 4.3  | 2.1   |
| 65385    | 25      | 28                | 1    | 1 1/4 | Lead-free gunmetal | 90    | 7.2  | 4.4   | 4.9  | 2.7   |

| <i>Art. no.</i> | <i>DN</i> | <i>d<sub>ø</sub><br/>mm</i> | <i>Rp<br/>"</i> | <i>G<br/>"</i> | <i>Product material</i> | <i>arc<br/>°</i> | <i>L<br/>cm</i> | <i>L1<br/>cm</i> | <i>Z<br/>cm</i> | <i>Z1<br/>cm</i> |
|-----------------|-----------|-----------------------------|-----------------|----------------|-------------------------|------------------|-----------------|------------------|-----------------|------------------|
| 65386           | 32        | 35                          | 1 1/4           | 1 1/2          | Lead-free gunmetal      | 90               | 8               | 5                | 5.4             | 3.1              |
| 65387           | 40        | 42                          | 1 1/2           | 1 3/4          | Lead-free gunmetal      | 90               | 8.7             | 5.3              | 5.7             | 3.4              |
| 65388           | 50        | 54                          | 2               | 2 3/8          | Gunmetal                | 90               | 10.1            | 6.4              | 6.6             | 4.1              |