


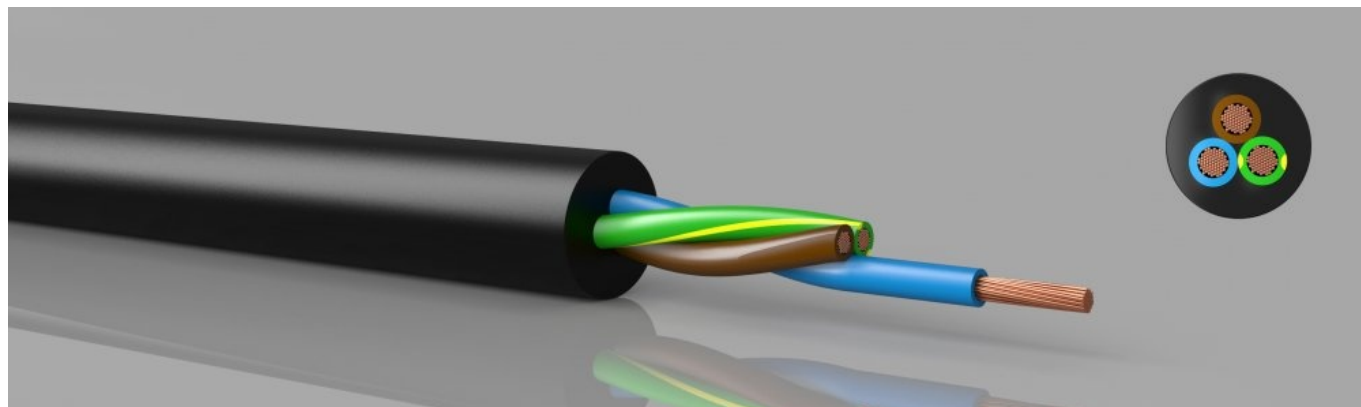

✓ installation ✓ RoHS ✓ REACH ✓ CE

H07RN-F

heavy rubber cable, harmonised

Application / Description

Heavy rubber cable for use under medium load in indoor and outdoor environments. Ideal as a flexible connection cable for devices or for fixed installation.

Product range

Order-No.	Type	Cross section qmm	Structure of conductor mm	O.D. approx. mm	weight kg/km	Cu-weight kg/km
672325000	H07RN-F3G2.5	2,50	50 x 0,25	14,00	205,0	72,0
672515000	H07RN-F5G1.5	1,50	30 x 0,25	14,40	210,0	72,0
672525000	H07RN-F5G2.5	2,50	50 x 0,25	17,00	305,0	120,0



Variant data

Construction [depending on the article](#)

Construction / data

Conductor	bare stranded copper wire
Core insulation	Special Rubber
Core code	acc. to VDE 0293 (HD308)
Outer jacket	Special Rubber

Technical characteristics

Temperature range	static: -40 °C to +85 °C dynamic: -25 °C to +60 °C
Bending radius static	> 4 x O.D.
Bending radius dynamic	> 6 x O.D.
Operating voltage U ₀	450 V
Operating voltage U	750 V

Technische Änderungen und Irrtümer vorbehalten. Die Eignung für einen konkreten Verwendungszweck muss vom Kunden geprüft werden. Achtung: Gefahr eines elektrischen Schlages, Produkt darf nur von Fachpersonal verarbeitet werden!

Technical changes and errors reserved. The suitability for a specific purpose must be checked by the customer. Warning: Risk of electric shock, the product may only be handled by qualified personnel

