


C87, Film, Film/Foil Polypropylene, Motor Run, 6 uF, 5%, 450 VAC

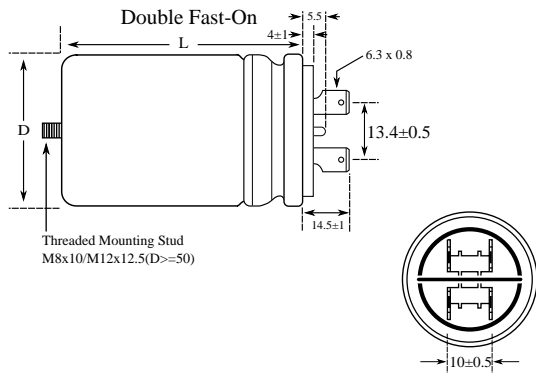

General Information

Supplier:	KEMET
Series:	C87
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Aluminum Case, Plastic Cover, Spun Seal
Features:	Spun Seal, Safety Class S2, UL_94 V0 Disk
RoHS:	Yes
Lead:	Fast On (2+2)
Qualifications:	UL, VDE, CQC, CSA (240VAC), UL_94 V0 Disk

Dimensions

D	25mm +1mm
L	56.5mm +/-2mm

Packaging Specifications

Mounting:	Bolt - M8x10
Packaging:	Bulk, Bag
Packaging Quantity:	62

Specifications

Capacitance:	6 uF
Capacitance Tolerance:	5%
Voltage AC:	450 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85°C
Max dV/dt:	20 V/us