


**Part Number :** [150150629](#)

**Product Description :** 0.30mm Pitch Premo-Flex Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 29 Circuits

**Series Number :** 15015

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

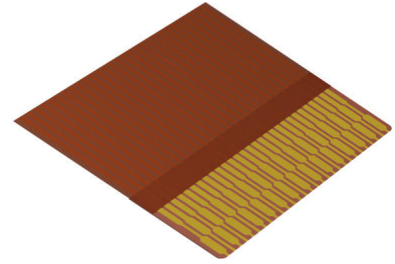

---

## Documents & Resources

### Drawings

[150150629 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


### Specifications

[PS-15015-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |  |
|--------------------|--|
| GADSL/IMDS         | Not Relevant   |
| China RoHS         | <br>per SJ/T 11365-2006 |
| EU ELV             | Not Relevant   |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21   |
| REACH SVHC         | Not Contained per D(2025)4165-DC<br>(25 June 2025)   |
| EU RoHS            | Compliant per EU 2015/863  |

### [Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

### [Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

|              |  |
|--------------|--|
| Status       | Active   |
| Category     | Flat-Flexible Cable (FFC)  |
| Series       | 15015  |
| Description  | 0.30mm Pitch Premo-Flex Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 29 Circuits |
| Product Name | Premo-Flex FFC Jumper  |
| UPC          | 884982822634   |

### Electrical

|                               |           |
|-------------------------------|-----------|
| Current - Maximum per Contact | 0.2A      |
| Voltage - Maximum             | 50V AC/DC |

### Physical

|                               |                 |
|-------------------------------|-----------------|
| Cable Length                  | 152.00mm        |
| Circuits (Loaded)             | 29              |
| Contact Layout Type           | A (same side)   |
| Design Feature                | Miniaturization |
| Material - Plating Mating     | Gold            |
| Net Weight                    | 1.000/g         |
| Packaging Type                | Bag             |
| Pitch - Mating Interface      | 0.30mm          |
| Temperature Range - Operating | -40° to +105°C  |

|                   |                 |
|-------------------|-----------------|
| Termination Style | FFC Connector   |
| Wire/Cable Type   | Flat Flex Cable |
| Wire Size (AWG)   | N/A             |

---

## Mates With / Use With

### Mates with Part(s)

| Description  | Part Number       |
|--|-------------------|
| 0.30mm Pitch Easy-On Back Flip FPC Connector, Right-Angle, Surface Mount, Dual Contact Style, 1.15mm Mated Height, 29 Circuits | <u>5025982993</u> |

---

This document was generated on Sep 23, 2025