


LED PAR38

SLD561422

14,0 W - 1400lm - 3000K

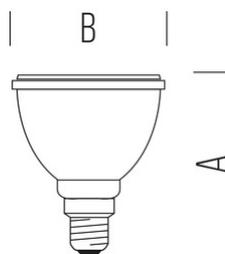

| DIMENSIONS | A | B | C |
|------------|-----|-----|-----|
| 1 | 136 | --- | 121 |

| GENERAL INFORMATIONS | |
|----------------------------|---------------|
| Code | SLD561422 |
| Ean | 8031453014285 |
| Family | LED PAR38 |
| Technology | LED |
| Energy class | A+ |
| Operating temperature (°C) | -20 - +40 |

| PACKAGING | |
|-----------|-----|
| Packaging | BOX |
| Pack | 10 |

| LIGHTING DATA | |
|----------------------------|-------|
| Kelvin (°) | 3000 |
| Lumen | 1400 |
| Useful Lumen (lm) | 1260 |
| Candela (cd) | 4000 |
| Beam (°) | 25 |
| Luminous efficacy (lm / W) | 100,0 |
| Color rendering (CRI) | >80 |

| TECHNICAL FEATURES | |
|------------------------------|-----------|
| Base | E27 |
| Power (W) | 14,0 |
| Equivalence (W) | 120 |
| Supply voltage (V) / Max (V) | 100 / 240 |
| Power frequency (Hz) | 50/60 |
| Power factor | >0,80 |
| Dimmer compatibility | NO |