


FEATURES

- **Nylon Material:** Provides durability and resistance to wear and tear.
- **55kg Tensile Strength:** Ensures strong and secure bundling of cables.
- **Non-Releasable Design:** Offers a permanent solution for cable management.
- **UL 94 V-0 Fire Behaviour:** Meets stringent fire safety standards.
- **RoHS Compliant:** Environmentally friendly and safe for use in various applications.
- **105mm Maximum Bundle Diameter:** Accommodates large bundles of cables.
- **85°C Maximum Operating Temperature:** Suitable for use in high-temperature environments.

RS PRO 380mm Nylon Cable Tie, 55kg Tensile Strength

RS Stock No: 656-040

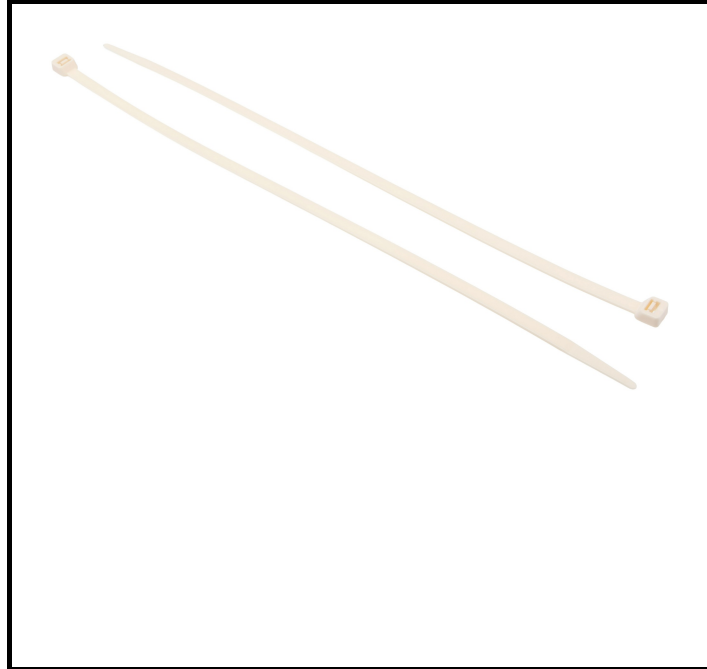

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a robust and reliable cable tie solution designed for securing and organising cables in various environments. With a length of 380 mm and a tensile strength of 55 kg, this non-releasable cable tie ensures a secure hold, making it ideal for both industrial and commercial applications.

General Specifications

Colour	White
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	55 kg

Protection Category

Fire Behaviour	UL 94 V-0
UV Resistant	No

Mechanical Specifications

Length	380 mm
Material	Nylon
Maximum Bundle Diameter	105 mm
Width	7.6 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	RoHS, UL94V-0
---------------------	---------------

