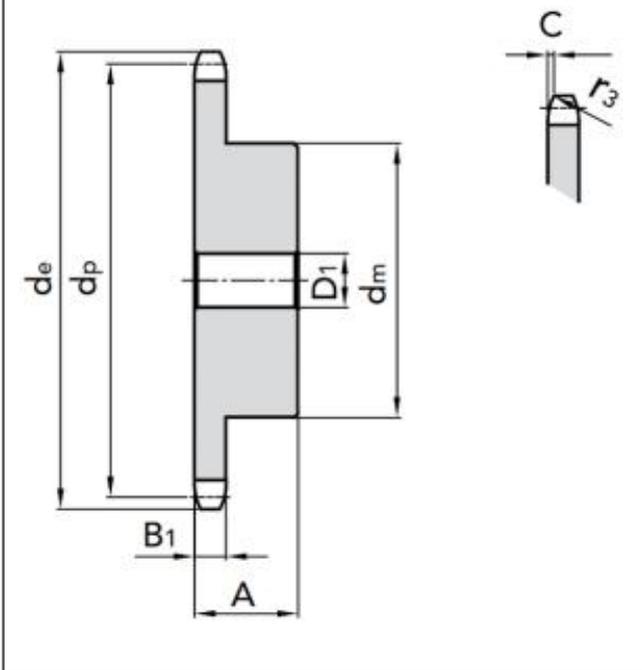
 


10125016

1in x 17.02 mm - Chain sprockets ISO

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Number of teeth (T)	16
de (DE) mm	141.32
dp (DP) mm	130.20
Part number (CODE)	10125016
dm (DM) mm	100
D1 (D1) mm	20
A (A) mm	45
Tooth radius r3 (R3) mm	26
Radius width C (C) mm	2.5
Sprockets tooth width B1 (B1) mm	16.2
Weight (WEIGHT) kg	3.14
Material (MAT)	STEEL C 45