


Technical data

KH4060LL/3AS

Ball sleeves



VISUAL (S)

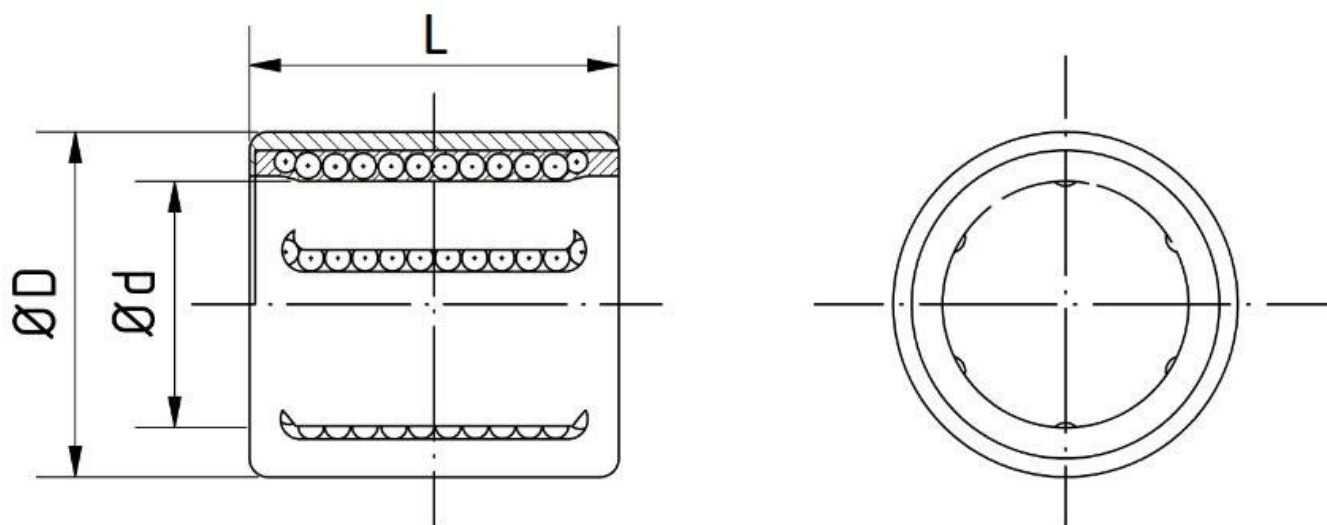

PRODUCT DEFINITION

Brand	NTN
Design type	KH
Ball bushings category	Ball sleeves
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	hardened steel sleeve
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter	40 mm
D - External diameter	52 mm
L - Length	60 mm
Number of ball rows	8
Mass	0,18 kg

PRODUCT PERFORMANCE

Cmin	4250000 mN
Cmax	4250000 mN
C0min	4000000 mN
C0max	4000000 mN
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	353,15 °K

