


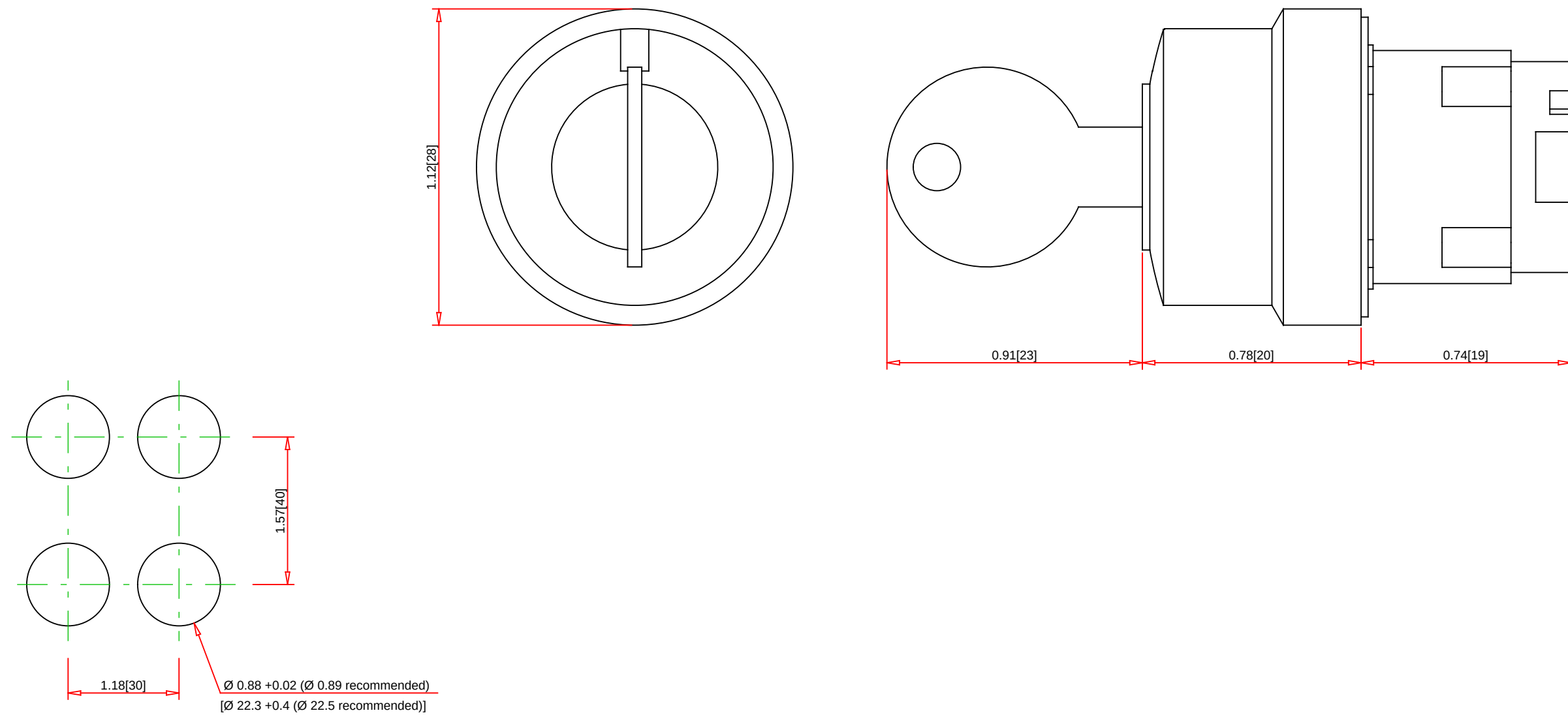

Note: - Drawings Not To Scale - Drawings Subject to Change Without Notice - Dimensions are inches next to [Millimeters]		Part No.: ZB4BG02		Schneider Electric Schneider Electric United States North American Division Boston One Campus 800 Federal Street Andover, MA 01810, USA Phone:+1 8773425173 Email: CCC@us.schneider-electric.com	
Technical Information: JL Listed: Yes JL File: E164353 CCN NKCR CSA Approval: Yes CSA File: LR44087 Class 3211 03 CE: Yes RoHS: Yes Bezel Material: Chromed Zinc NEMA / IP Rating: NEMA 1/2/3/4/4X/13; IP66 Key Number: Ronis 455 Key Removal: left Max. # of Contact Blocks: 6 Button Marking: none				Specification: Description: 22mm 2 Pos Key Selector Operator Type: Non-Illuminated Operator Action: Maintained Button Type: n/a Bezel Type: Metal Color: Black Head Type: Round	