




# OSRAM ECOPACK®-FH OSRAM ECOPACK®-FH DIM

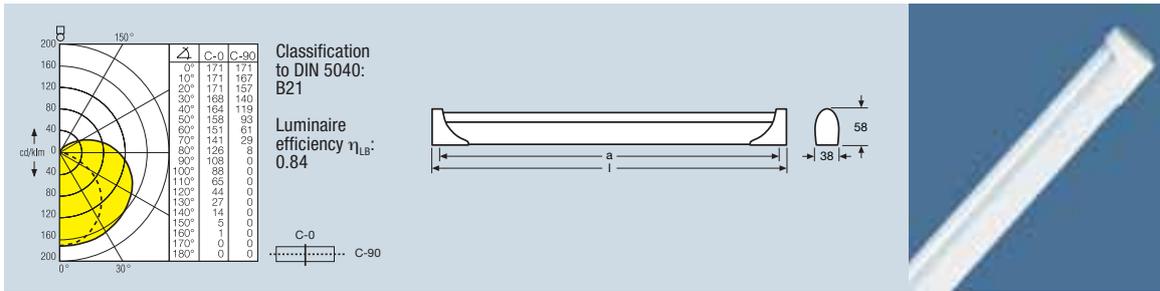

Product reference	Product number	COLOR	W	V	Hz	$l$ [mm]	$b$ [mm]	$h$ [mm]	$a$ [mm]	
<b>OSRAM ECOPACK®-FH</b>										
72601	4050300513249	white	14	230-240	0, 50-60	584	38	58	538	4x1
72602	4050300513263	white	21	230-240	0, 50-60	884	38	58	838	4x1
72603	4050300513287	white	28	230-240	0, 50-60	1184	38	58	1138	4x1
72604	4050300513300	white	35	230-240	0, 50-60	1484	38	58	1438	4x1
<b>OSRAM ECOPACK®-FH DIM</b>										
72611	4050300659213	white	14	230-240	0, 50-60	584	38	58	538	4x1
72612	4050300659237	white	21	230-240	0, 50-60	884	38	58	838	4x1
72613	4050300659251	white	28	230-240	0, 50-60	1184	38	58	1138	4x1
72614	4050300659275	white	35	230-240	0, 50-60	1484	38	58	1438	4x1

### Description and features

OSRAM ECOPACK®-FH are extremely economical. They provide the same light using less power than comparable batten luminaires of the same length with 26 mm fluorescent lamps.

- Compact electronic batten luminaire for fixed connection
- With innovative FH® fluorescent lamp
- With QUICKTRONIC® QT-FH or QT-FH DIM electronic control gear
- Long lamp life thanks to cut-off technology
- With prismatic lamp cover for uniform light distribution

### OSRAM ECOPACK®-FH DIM:

- Dimmable from 100% to 1%
- Control via 1-10 V DC control signal

### Technical data and equipment

- Equipped with LUMILUX® T5 FH 31-830 HE
- 

### OSRAM ECOPACK®-FH DIM:

- Also suitable without cover for LUMILUX® T5 FQ HO

### Accessories

- Sensors for OSRAM ECOPACK®-FH DIM (for a description see page 92)
- Louvre (for a description see page 93)
- Pendant kit (for a description see page 93)

