
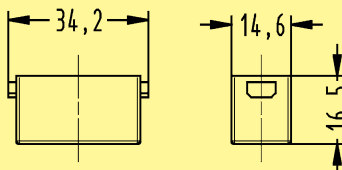

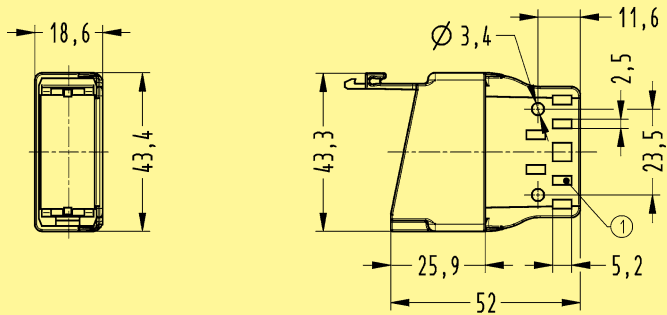

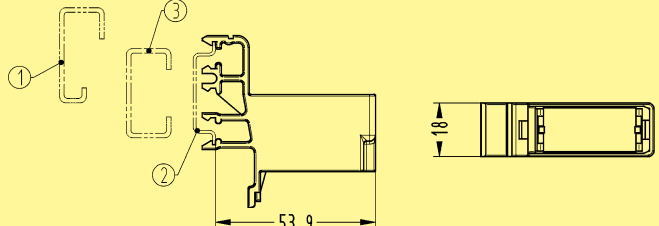

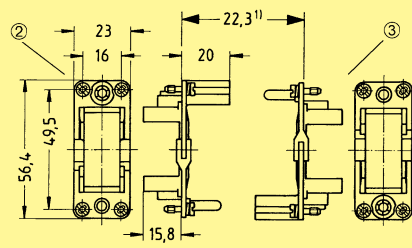


Identification	Part number	Drawing	Dimensions in mm
<p>Han-Modular® Dummy module to fill up module spaces not in use in the frame</p> 	<p>09 14 000 9950</p>		
<p>Module clamp with strain relief</p>  <p>Delivery comprises one module clamp.</p>	<p>09 14 000 0312</p>	 <p>1 For cable ties with max. 5 mm width</p>	
<p>Module clamp for rail</p>  <p>Delivery comprises one module clamp.</p>	<p>09 14 000 0313</p>	 <p>1 G-rail DIN EN 60 715-G32 2 rail DIN EN 60 715-35 x 7.5 with 1 mm thickness or -35 x 15 with 1.5 mm thickness 3 C-rail DIN EN 60 715-C30</p>	
<p>Frame for 1 module</p>  <p>in housing Han® 10 A</p>	<p>09 14 000 0304</p>	 <p>1 Distance max. 23.5 mm 2 Hoods 3 Housings</p>	