



Figure similar

SITOR cylindrical fuse link, 10 x 38 mm, 32 A, gR, Un AC: 690 V, Un DC: 250 V

Model			
product brand name		SETRON	
product designation		SITOR cylindrical fuse link	
General technical data			
operating class of the fuse link		gR	
type of voltage of the operating voltage		AC	
supply voltage at DC		250 V	
Main circuit			
operational current rated value		32 A	
Product details			
product component striker		No	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		9 g	
Approvals Certificates			
General Product Approval		other	Environment



[Confirmation](#)


[Environmental Con-
firmations](#)

Environment

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC1032-0MK>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3NC1032-0MK>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1032-0MK
CAx-Online-Generator

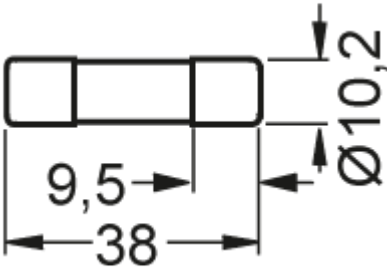

last modified: 4/11/2025 

