


# Dimensions

mm  
inch


## Two- or Four Hole Panel Mounting

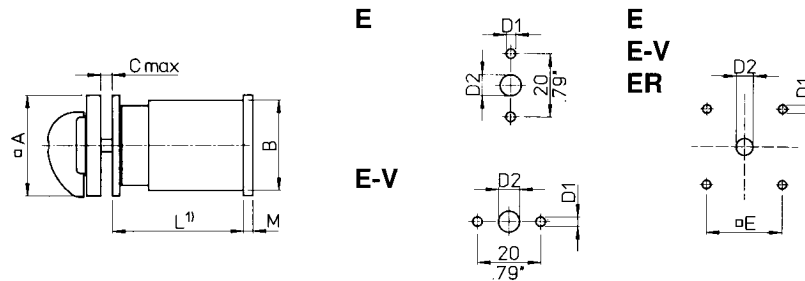

	CA4	CA10	CA10B	C315											
	CA4-1	CA11	CA10B	L-switches	L-switches										
	CA20	CAD11	CA11B	Size S2	Size S3										
		CAD12	CA20B												
<b>A</b>	30 1.18	48 1.89	48 1.89	48 1.89	64 2.52	64 2.52	64 2.52	64 2.52	64 (88) 2.52 (3.46)	88 3.46	88 3.46	88 3.46	88 3.46	88 3.46	130 5.12
<b>B</b>	28 1.10	45 1.77	43 1.69	46 1.81	43 1.69	56 2.20	56 2.20	58 2.28	60 2.36	66 2.6	84 3.3	84 3.3	88 3.46	88 3.46	126 4.96
<b>C</b>	4 .16	4 .16	4 .16	4 .16	4 .16	4 .16	4 .16	4 .16	4 .16	4 .16	5,5 .22	5,5 .22	5,5 .22	5,5 .22	7 .28
<b>D1</b>	3,2 .13	5 .20	5 .20	5 .20	5 .20	5 .20	5 .20	5 .20	5 .20	5 (6) .20 (.24)	6 .24	6 .24	6 .24	6 .24	7 .28
<b>D2</b>	8 - 11 .31 - .43	8 - 15 .31 - .59	8 - 15 .31 - .59	8 - 15 .31 - .59	8 - 15 .31 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	13 - 17 .51 - .67	13 - 17 .51 - .67	13 - 17 .51 - .67	13 - 17 .51 - .67	15,5 - 20 .61 - .79
<b>E</b>	-	36 1.42	36 1.42	36 1.42	36 1.42	48 1.89	48 1.89	48 1.89	48 1.89	48 (68) 1.89 (2.68)	68 2.68	68 2.68	68 2.68	68 2.68	104 4.09
<b>M</b> <sup>2)</sup>	-	4,5 .18	4,5 .18	4,5 .18	4,5 .18	5 .2	5 .2	6,5 .26	6,5 .26	7,5 .3	7,5 .3	9,4 .37	9,4 .37	27,5 1.08	11,9 .47

2) M, additional length for mounting ER only  
\*Dimensions in brackets for ER mounting plate only

## EG EG24





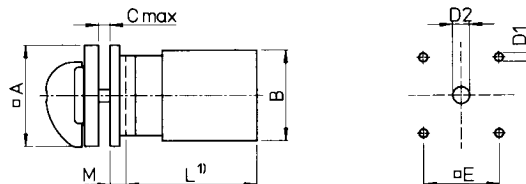


	CA10	CA11	CA10B	C125					
	CAD11	CA20	CA25	L-switches	L-switches				
	CAD12	CA20	CA25	Size S2	Size S2				
<b>A</b>	64 2.52	64 2.52	64 2.52	64 2.52	88 3.46	88 3.46	88 3.46	130 5.12	130 5.12
<b>B</b>	43 1.69	45 1.77	46 1.81	43 1.69	58 2.28	60 2.36	66 2.6	84 3.3	88 3.46
<b>C</b>	4 .16	4 .16	4 .16	4 .16	5,5 .22	5,5 .22	5,5 .22	7 .28	7 .28
<b>D1</b>	5 .20	5 .20	5 .20	5 .20	6 .24	6 .24	6 .24	7 .28	7 .28
<b>D2</b>	10 - 15 .39 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	10 - 15 .39 - .59	13 - 17 .51 - .67	13 - 17 .51 - .67	13 - 17 .51 - .67	15,5 - 20 .61 - .79	15,5 - 20 .61 - .79
<b>EG</b>									
<b>EG24</b>									
<b>D2</b>	19 - 22 .75 - .87	19 - 22 .75 - .87	19 - 22 .75 - .87	19 - 22 .75 - .87	26 - 30 1.02 - 1.18	26 - 30 1.02 - 1.18	26 - 30 1.02 - 1.18	22 - 25 .87 - .98	22 - 25 .87 - .98
<b>E</b>	48 1.89	48 1.89	48 1.89	48 1.89	68 2.86	68 2.86	68 2.86	88 3.46	88 3.46
<b>EG</b>									
<b>M</b>	7,5 .30	7,5 .30	7,5 .30	7,5 .30	1,5 .06	1,5 .06	1,5 .06	2 .08	2 .08
<b>EG24</b>									
<b>M</b>	10,5 .41	10,5 .41	10,5 .41	10,5 .41	-	-	-	-	-

**Dimensions**      mm  
                         inch

**Additional Length**

  **Terminal lugs for switches C315, C316 and L switches**

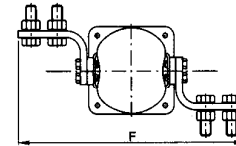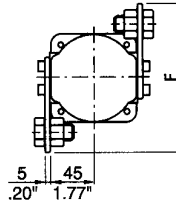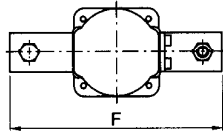

C315  
C316  
L400  
L600

L800  
L1200  
L1600

L2000

F	L350	L630	L1000	L1250	L351	L631	L1001	L1251	C315			L800	L1600
									C316	L400	L600	L1200	L2000
	190	220	230	240	138	148	148	148	150	180	208	256	326
	7.48	8.66	9.06	9.45	5.43	5.83	5.83	5.83	5.91	7.09	8.19	10.08	12.83

**Length L**

Stages	CA10											C125		C315		
	CA4	CAD11	CA11	CA20	CA25	CA10B	CA11B	CA20B	CA25B	C26	C32	C42	C43	C80	L switches Size S2	L switches Size S3
1	30	33,5	36,7	37,7	39	38,9	42,1	43,1	44,4	42	46,8	50,8	59	61,5	67,5	78,6
	1.18	1.32	1.44	1.48	1.51	1.53	1.66	1.70	1.75	1.65	1.84	2.00	2.32	2.42	2.66	3.09
2	38	43	49,4	50,4	53	49,4	54,8	55,8	58,4	54,7	64,3	72,3	80,5	88,0	100	117,2
	1.50	1.69	1.94	1.98	2.09	1.91	2.16	2.20	2.30	2.15	2.51	2.85	3.17	3.46	3.94	4.61
3	46	52,5	62,1	63,1	67	57,9	67,5	68,5	72,4	67,4	81,8	93,8	102	114,5	132,5	155,8
	1.81	2.07	2.44	2.48	2.64	2.28	2.66	2.70	2.85	2.65	3.22	3.69	4.02	4.51	5.22	6.13
4	54	62	74,8	75,8	81	67,4	80,2	81,2	86,4	80,1	99,3	115,3	123,5	141	165	194,4
	2.13	2.44	2.94	2.98	3.19	2.65	3.16	3.20	3.40	3.15	3.91	4.54	4.86	5.55	6.50	7.65
5	62	71,5	87,5	88,5	95	76,9	92,9	93,9	100,4	92,8	116,8	136,8	145	167,5	197,5	233
	2.44	2.81	3.44	3.48	3.74	3.03	3.66	3.70	3.95	3.65	4.60	5.39	5.71	6.59	7.78	9.17
6	70	81	100,2	101,2	109	86,4	105,6	106,6	114,4	105,5	134,3	158,3	166,5	194	230	271,6
	2.76	3.19	3.94	3.98	4.29	3.40	4.16	4.20	4.50	4.15	5.29	6.23	6.56	7.64	9.06	10.69
7	78	90,5	112,9	113,9	123	95,9	118,3	119,3	128,4	118,2	151,8	179,8	188	220,5	262,5	310,2
	3.07	3.56	4.44	4.48	4.84	3.78	4.66	4.70	5.05	4.65	5.96	7.06	7.40	8.68	10.33	12.21
8	86	100	125,6	126,6	137	105,4	131	132	142,4	130,9	169,3	201,3	209,5	247	295	348,8
	3.39	3.94	4.94	4.98	5.39	4.15	5.16	5.20	5.60	5.15	6.67	7.93	8.25	9.72	11.61	13.73
9	94	109,5	138,3	139,3	151	114,9	143,7	144,7	156,4	143,6	186,8	222,8	231	273,5	327,5	387,4
	3.70	4.31	5.44	5.48	5.94	4.52	5.66	5.70	6.15	5.65	7.36	8.77	9.09	10.77	12.89	15.25
10	-	119	151	152	165	124,4	158,4	157,4	170,4	158,3	204,3	244,3	262,2	300	360	426
	-	4.68	5.94	5.98	6.50	4.90	6.16	6.20	6.70	6.15	8.04	9.62	9.54	11.81	14.17	16.77
11	-	128,5	163,7	164,7	179	133,9	169,1	170,1	184,4	169	221,8	265,8	274	326,5	392,5	464,6
	-	5.06	6.44	6.48	7.05	5.27	6.66	6.70	7.25	6.65	8.73	10.46	10.79	12.85	15.45	18.29
12	-	138	176,4	177,4	193	143,4	181,8	182,8	198,4	181,7	239,3	287,3	295,5	353	425	503,2
	-	5.43	6.94	6.98	7.60	5.65	7.16	7.20	7.80	7.15	9.42	11.31	11.63	13.90	16.73	19.81