


## Features

- Lightweight and flexible
- BS 5342 Type 2 A
- Available in black and red colour
- Length 20m

## RS PRO Hose Pipe

RS Stock No.: **486-647, 486-495, 486-536**

**486-631, 486-530, 486-546**

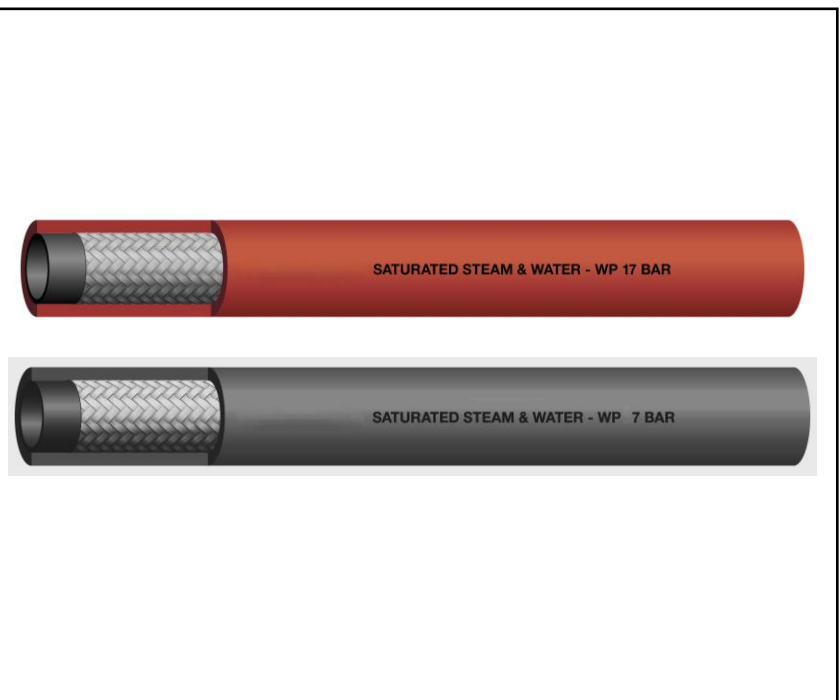

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

Red, heavy-duty, spiralized steel house manufactured to BS 5342 Type 2 Class A.

For use in the industry, saturated steam and hot water are used in laundries, dairies, slaughterhouses, power stations, etc. Also available in black.

For steam, it must be installed using special connectors. Crimped-on fittings are recommended for pressurised steam.

## General Specification

Brand	RS PRO
Features	Flexible
Materials	EPDM
Colour	Red (486-647, 486-495, 486-536), Black (486631, 486530, 486546)
Length	20m
Suitable Applications	Steam
Maximum Operating Temperature	+235°C
Minimum Operating Temperature	-30°C
Maximum Working Pressure	Red 17 bar, Black 7 bar
Hose Pipe Action	Transfer
Standards Met	BS 5342 Type 2 A
Bend Radius	130mm

### Products in series

Stock No.	Lenght	Inner Diameter	Outer Diameter	Colour
486-647	20m	13mm	25mm	Red
486-495	20m	19mm	33mm	Red
486-536	20m	25mm	40mm	Red
486-631	20m	13mm	25mm	Black
486-530	20m	19mm	33mm	Black
486-546	20m	25mm	40mm	Black