


Adapter plug

ESTGH040MSS0,12E04 (M20)

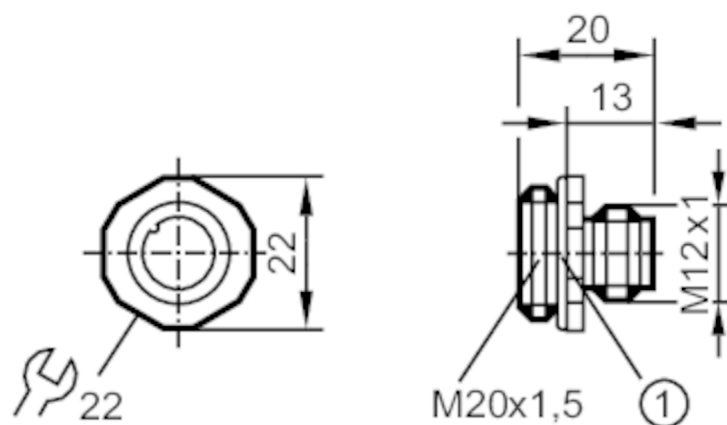

Electrical data

Operating voltage	[M]	< 45 AC / < 70 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	19.6
Mounting thread		M20
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.12 m, PVC; 4 x 0.25 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated



E11295



Adapter plug

ESTGH040MSS0,12E04 (M20)

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white