




ENGLISH

Datasheet

Stock No: 522-452

RS Pro 8 Core YY Control Cable Unscreened Polyvinyl Chloride PVC Sheath

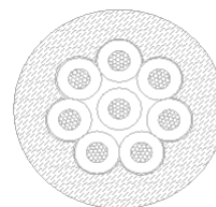

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V): 300

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.25 \pm 0.008 \times 30$

Insulation: PVC

Insulation Dia. (mm): $2.8 \pm 0.1 \times 8C$

Filler: Chalk

Jacket: PVC

Outer Dia. (mm): 11.35 ± 0.25

Colour:

The color of the insulation: Black x 7 , Yellow/Green

The jacket color: Grey

Marking(3times/m):

RS 522452 YY/NR 8 Core x 1.5mm^2

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) : <13.7

Min.Insulation DC Resistance at 20°C ($\text{M}\Omega \cdot \text{KM}$) : >500

Current Rating : 16A