



## Standard steel cable cutters



### Description:

- Blade inserts in high-performance steel.
- Compact and powerful with ergonomic grips.
- Capacity: - 8 mm for 60 - 100 kg/mm<sup>2</sup> soft steel cable. - 7 mm for 130 - 160 kg/mm<sup>2</sup> hard steel cable. - 6 mm for 60 kg/mm<sup>2</sup> round cable.
- Spare blades: 996.L8.

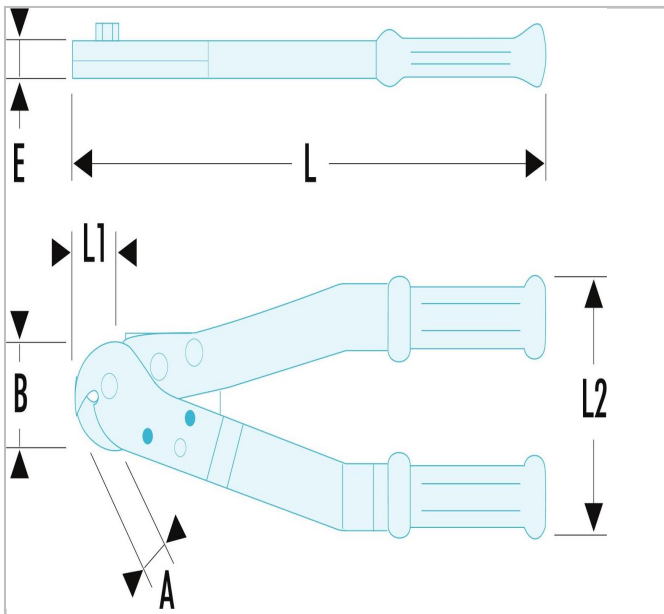

	A [mm]	Length L [mm]	Length L1 [mm]	Length L2 [mm]	Thickness E [mm]	Head Width B [mm]
<b>996.8</b>	12.0	340.0	21.0	115 - 470	16.0	42.0