




## HST-DE RX7s 70W HO 2000K

Article number: 146175

BAI HPS HST-DE RX7s 70W 2000K 6300lm 20x114mm NAV-TS Clear High pressure sodium-vapour lamp

Gas discharge lamp with various applications.

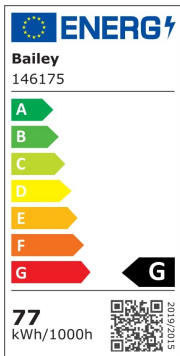


### General ETIM properties

ETIM group	Lamps
ETIM class	High pressure sodium-vapour lamp
Name	HST-DE RX7s 70W HO 2000K
Brand	Bailey
Productseries	HID
Producttype	HST-DE

## ETIM specifications

Socket	RX7s
Lamp power [W]	70
Lamp shape	Tube, single-ended
Colour temperature [K]	2000
Lamp designation	Other
Diameter [mm]	20
Total length [mm]	114
Lighting for plants	Yes
Colour rendering index CRI	20-39
Lamp efficacy [lm/W]	90
External ignitor required	Yes
External ballast required	Yes
Luminous flux [lm]	6300
Model	Clear
Replacement for mercury vapour lamp	No
Weighted energy consumption in 1000 hours [kWh]	77
Average nominal lifetime [h]	28000
Number of discharge tubes	1
Energy efficiency class according to EU regulation 2019/2015	G
Mercury-free	No

## Complementary articles

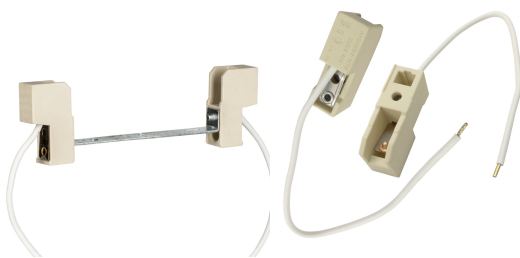

**141208**  
Lampholder RX7s 114.2/70W 6A  
1000V T250°C 250mm

**146206**  
VS 100913 RX7s Lampholder  
Cable 200mm 1pce