

Euromas Polymas

Enclosure



PK 115

Order no.: 38115000

* = Available on request.

Characteristics

Colour of enclosure group
silver-grey

Protection class
IP 65

Enclosure Material
PA 6-GB 30, seal made of CR; for details see Technical Information


Scope of delivery
Lid and base, lid screws made of V2A

Note
G = Model with crystal clear lid.

Dimensions

Dimensions
175 x 80 x 57 mm

Product drawing

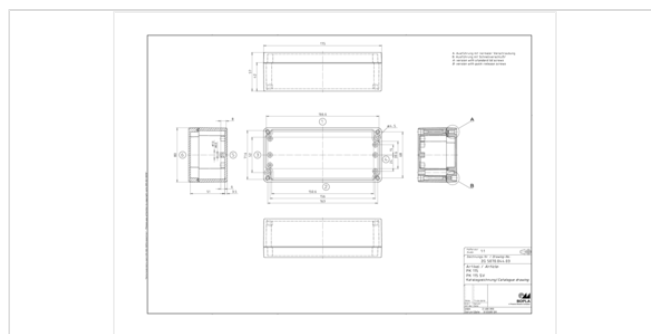

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

Technical documentation / Downloads

Technical drawings

3D product data in STEP format: Registration necessary
Product drawing in PDF format: 38115000 PK-115.pdf (54.4 KB)
Product drawing in DXF format: 38115000 PK-115.dxf (542.3 KB)
Drawing for mechanical processing: 38115000 PK-115-G.dxf (789.4 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

20.09.2019

Product information

Euromas Polymas GB.pdf (306.5 KB)


Matching accessories



Mounting panels for PK 105 - 115, galvanised sheet steel

21001300 M

For A 115, PK 115

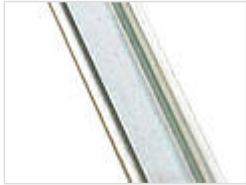

DIN rails for PK 105 - 115, DIN EN 60715 TH 15

21003000* TS 15

For A 115, PK 115



Screws (SHR) and distance bolts (DIBLZ) for mounting bosses in plastic enclosures

59006210 SHR Z KA35x8

SD = 3.5 / ND = 2.8 / KD = 6.1