


188300 AEVC-80-10-I-P-A Short-stroke cylinder - Series: All

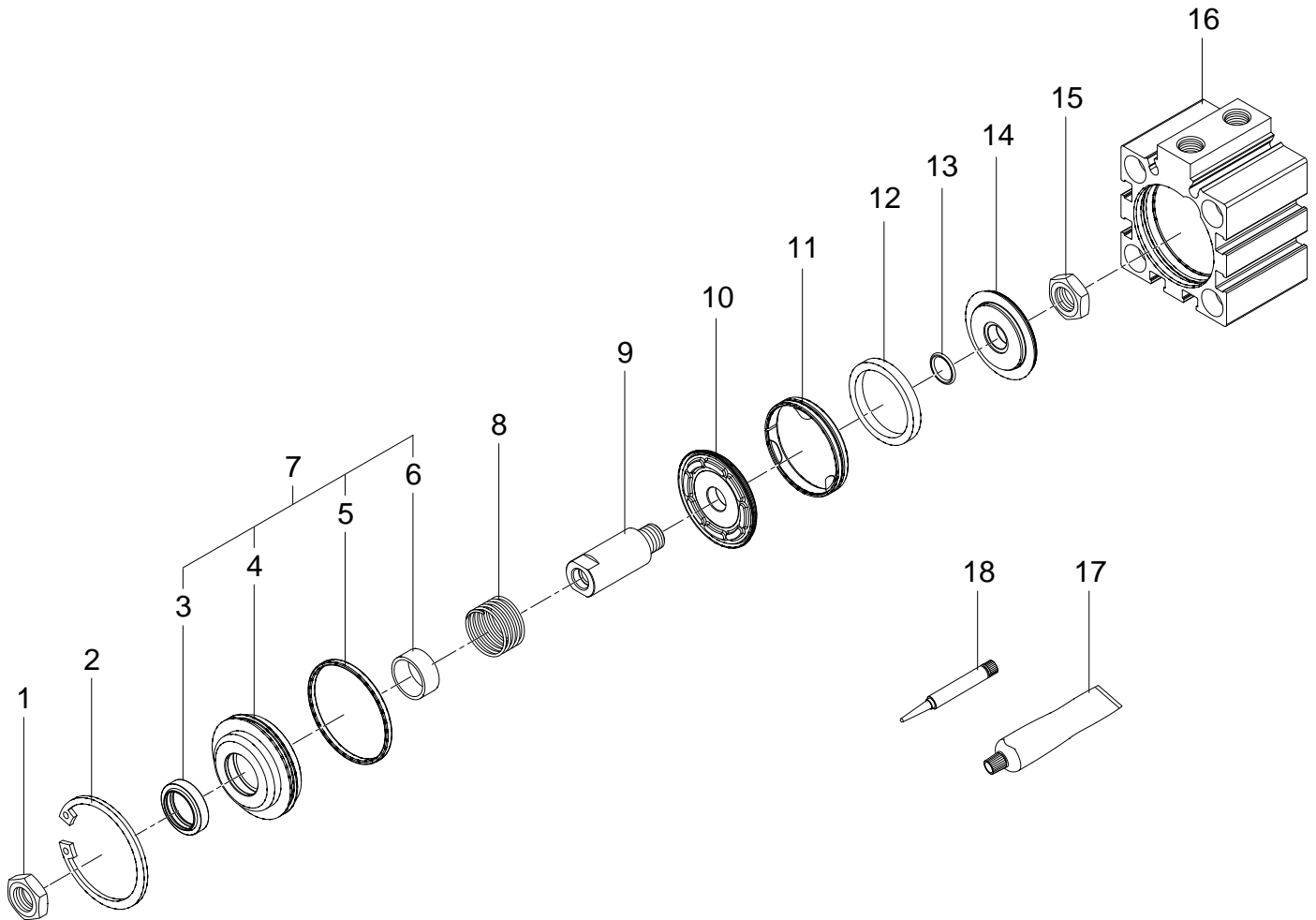

188300 AEVC-80-10-I-P-A Short-stroke cylinder - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	673683	AEVC- 80-A-P-A Set of wearing parts	Spare parts: 3, 5, 10, 11, 13, 14, 17, 18	1	PC
1	200127	DIN 439-B-M16X1,5-04 Hex nut		1	PC
2	236749	DIN 472-82X2,5 Retaining ring		1	PC
3	359748	WIFC1-20X25X4,6-TPE-U Wiper seal	Grease using during assembly. See position 17	1	PC
4		AEVC/ADVC-80 Bearing cap	Not available separately, see position 7	1	PC
5		B-79X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position 7 Grease using during assembly. See position 17	1	PC
6		GLWSM-2023-12 Plain bearing	Not available separately, see position 7	1	PC
7	5265781	AEVC/ADVC-80 Bearing cap module		1	PC
8	338294	AEVU-80- -P-A Compression spring		1	PC
9	390165	IRA-20-S0037,35 Piston rod		1	PC
10		BA-K01E-080-WRB Sealing piston	Not available separately, see position A Grease using during assembly. See position 17	1	PC
11		BA-K01F-080 Guiding band	Not available separately, see position A Grease using during assembly. See position 17	1	PC
12	4760182	76,9X58X6BA-K01M-080 Ring magnet		1	PC
13		B-14X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 17	1	PC
14		BA-K01D-080-CFW Sealing piston	Not available separately, see position A Grease using during assembly. See position 17	1	PC
15	204153	DIN 439-B-M14X1,5-04 Hex nut	Use locking compound. See position 18 Tightening torque 63 Nm / 46.5 lbf ft	1	PC
16		ADVC- 80- 10- -P-A Housing	Not available	1	PC
17	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
18	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC