

Actuator

45-
2T00.10K0.000

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-2T00.10K0.000>

Your product:



45-2T00.10K0.000 Actuator

FRONT

Front dimension: Ø 30 mm

Front form: Round

MOUNTING

Design: Raised

Mounting cut-out: Ø 22.3 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens cap colour: Colourless

Lens cap material: Plastic

Lens cap shape: flush

Lens cap optical effect: transparent

Illumination colour: Colourless

MECHANICAL CHARACTERISTIC

Weight: 0.012 kg

AMBIENT CONDITION

IP front protection: IP66, IP67, IP69K

Operating temperature: – 25 °C ... + 70 °C

Storage temperature: – 40 °C ... + 80 °C

Shock resistance:

According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance:

According to IEC 60068-2-6: 2 ... 500 Hz: 5 g

Climate resistance:

During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE**REACH:**

REACH compliant

RoHS:


RoHS compliant


OTHER**Short Description:**

Actuator, Ø 22.3 mm, Ø 30 mm, Round, IP66, IP67, IP69K, Colourless

Housing material:

Plastic

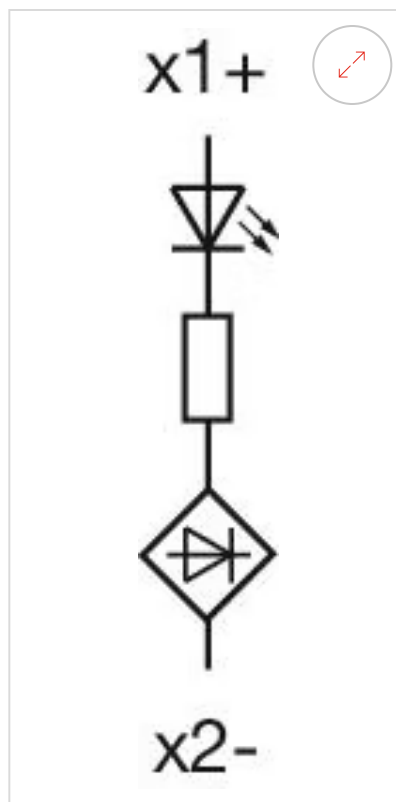Wiring diagrams:**Mounting cut-outs:**

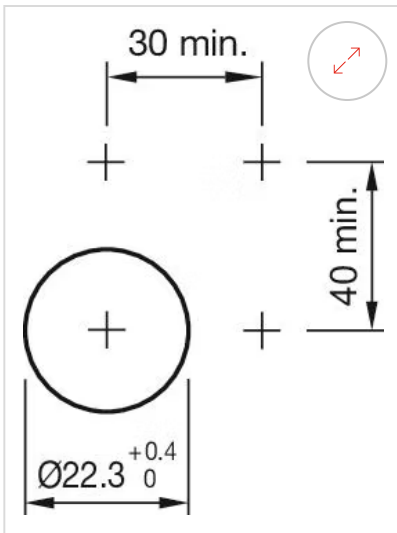

Dimension drawings:

