

## Product Table

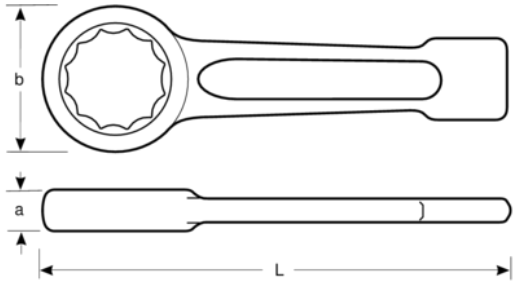
Slogging ring wrench, used with a hammer to tighten large bolts and nuts



Material: Aluminium Bronze

Non sparking

Die-forged

Fulfilling product standard DIN 7444



	 <b>g</b>	<b>B</b>	<b>a</b>	<b>L</b>	
NS104-17	190 g	32 mm	12 mm	145 mm	17 mm
NS104-19	180 g	32 mm	12 mm	145 mm	19 mm
NS104-20	225 g	38 mm	13 mm	155 mm	20 mm
NS104-22	220 g	38 mm	13 mm	155 mm	22 mm
NS104-24	210 g	42 mm	14 mm	165 mm	24 mm
NS104-25	210 g	42 mm	14 mm	165 mm	25 mm
NS104-26	315 g	46 mm	16 mm	175 mm	26 mm
NS104-27	315 g	46 mm	16 mm	175 mm	27 mm
NS104-28	315 g	46 mm	16 mm	175 mm	28 mm
NS104-29	430 g	50 mm	16 mm	185 mm	29 mm
NS104-30	430 g	50 mm	16 mm	185 mm	30 mm
NS104-31	430 g	53 mm	16 mm	185 mm	31 mm
NS104-32	420 g	53 mm	16 mm	185 mm	32 mm
NS104-33	490 g	55 mm	18 mm	200 mm	33 mm
NS104-34	490 g	55 mm	18 mm	200 mm	34 mm
NS104-35	520 g	58 mm	19 mm	205 mm	35 mm
NS104-36	520 g	58 mm	19 mm	205 mm	36 mm
NS104-37	620 g	61 mm	20 mm	215 mm	37 mm

NS104-38	620 g	61 mm	20 mm	215 mm	38 mm
NS104-39	620 g	61 mm	19 mm	215 mm	39 mm
NS104-40	680 g	64 mm	20 mm	225 mm	40 mm
NS104-41	680 g	64 mm	20 mm	225 mm	41 mm
NS104-42	680 g	64 mm	20 mm	225 mm	42 mm
NS104-43	680 g	64 mm	20 mm	225 mm	43 mm
NS104-44	890 g	73 mm	22 mm	235 mm	44 mm
NS104-45	890 g	73 mm	22 mm	235 mm	45 mm
NS104-46	890 g	73 mm	22 mm	235 mm	46 mm
NS104-47	890 g	73 mm	22 mm	235 mm	47 mm
NS104-48	1030 g	78 mm	23 mm	250 mm	48 mm
NS104-49	1030 g	78 mm	23 mm	250 mm	49 mm
NS104-50	1030 g	78 mm	23 mm	250 mm	50 mm
NS104-51	1030 g	78 mm	23 mm	250 mm	51 mm
NS104-52	1030 g	78 mm	23 mm	250 mm	52 mm
NS104-54	1300 g	86 mm	24 mm	265 mm	54 mm
NS104-53	1300 g	86 mm	24 mm	265 mm	53 mm
NS104-55	1300 g	86 mm	24 mm	265 mm	55 mm
NS104-56	1300 g	86 mm	24 mm	265 mm	56 mm
NS104-57	1300 g	86 mm	24 mm	265 mm	57 mm
NS104-58	1450 g	92 mm	26 mm	274 mm	58 mm
NS104-59	1450 g	92 mm	26 mm	274 mm	59 mm
NS104-60	1450 g	92 mm	26 mm	274 mm	60 mm
NS104-61	1450 g	92 mm	26 mm	274 mm	61 mm
NS104-62	1450 g	92 mm	26 mm	274 mm	62 mm
NS104-63	1800 g	102 mm	30 mm	398 mm	63 mm
NS104-64	1800 g	102 mm	30 mm	298 mm	64 mm
NS104-65	1800 g	102 mm	30 mm	298 mm	65 mm
NS104-66	1800 g	102 mm	30 mm	298 mm	66 mm
NS104-67	2200 g	108 mm	32 mm	320 mm	67 mm
NS104-68	2200 g	108 mm	32 mm	320 mm	68 mm
NS104-69	2200 g	108 mm	32 mm	320 mm	69 mm
NS104-70	2200 g	108 mm	32 mm	320 mm	70 mm
NS104-71	2200 g	108 mm	32 mm	320 mm	71 mm
NS104-72	2200 g	108 mm	32 mm	320 mm	72 mm

NS104-73	2720 g	113 mm	33 mm	326 mm	73 mm
NS104-74	2720 g	113 mm	33 mm	326 mm	74 mm
NS104-75	2720 g	113 mm	33 mm	326 mm	75 mm
NS104-76	2720 g	113 mm	33 mm	326 mm	76 mm
NS104-77	2720 g	113 mm	33 mm	326 mm	77 mm
NS104-78	3250 g	124 mm	34 mm	350 mm	78 mm
NS104-79	3250 g	124 mm	34 mm	350 mm	79 mm
NS104-80	3250 g	124 mm	34 mm	350 mm	80 mm
NS104-81	3250 g	124 mm	34 mm	350 mm	81 mm
NS104-82	3250 g	124 mm	34 mm	350 mm	82 mm
NS104-83	3915 g	130 mm	36 mm	355 mm	83 mm
NS104-84	3915 g	130 mm	36 mm	355 mm	84 mm
NS104-85	3915 g	130 mm	36 mm	355 mm	85 mm
NS104-86	3915 g	130 mm	36 mm	355 mm	86 mm
NS104-87	3915 g	130 mm	36 mm	355 mm	87 mm
NS104-88	4700 g	135 mm	39 mm	380 mm	88 mm
NS104-89	4700 g	135 mm	39 mm	380 mm	89 mm
NS104-90	4700 g	135 mm	39 mm	380 mm	90 mm
NS104-92	4700 g	135 mm	39 mm	380 mm	92 mm
NS104-94	4820 g	142 mm	39 mm	390 mm	94 mm
NS104-95	4920 g	142 mm	39 mm	390 mm	95 mm
NS104-98	6100 g	148 mm	43 mm	410 mm	98 mm
NS104-100	6100 g	148 mm	43 mm	410 mm	100 mm
NS104-105	6320 g	155 mm	43 mm	420 mm	105 mm
NS104-110	8250 g	162 mm	45 mm	445 mm	110 mm
NS104-115	8850 g	168 mm	45 mm	450 mm	115 mm
NS104-120	9930 g	182 mm	50 mm	480 mm	120 mm