

Wire harness for SCHURTER products



5120 filter inlet with wire harness



KD power entry module with wire harness



6600 outlet with wire harness

Description

- Customer specific wire harness to SCHURTER products
- Push mounted, soldered or screwed-on, from rear-side

Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [Mating Connectors](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [CAD-Drawings](#), [Accessories](#), [Detailed request for product](#)

Wire Harnessing

The wire harness service includes several types of ready to install wires, cables or wire harnesses with custom specific end terminal connections. The SCHURTER products such as IEC 60320 connectors, power entry modules or filter products with quick connect, solder or screw on terminals can be assembled with customer specific interconnection solutions.


The offered solution includes the specific selected SCHURTER product inclusive the individual configured wire harness.

Customer specific wire harness request:

<http://www.schurter.ch/en/Components/Connectors/Wire-Harness-Request>

Dimension

Schematics of a SCHURTER wire harness

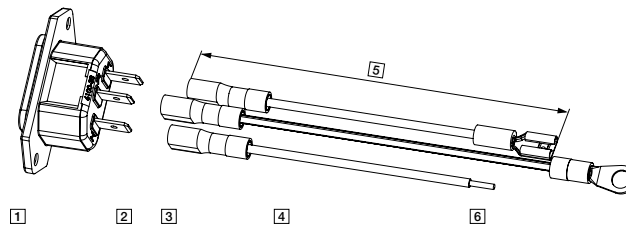

1) SCHURTER Type, 2) Terminal, 3) Wire terminal SCHURTER part, 4) Wire typ and color, 5) Wire length, 6) Wire terminal free end

All Variants

Suitable for	Description	Flexible wire length (mm)	interconnection	Description / Wire end terminals	Order Number
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 15A	150 mm	AWG16	L, N, PE, flexible wire, stripped	5120.0057.0
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 4A M5	150 mm	AWG18	L, N, PE, flexible wire, stripped	5120.0343.0
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 10A	150 mm	AWG18	L, N, PE, flexible wire, stripped	5120.1046.0
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 10A M5	150 mm	AWG18	L, N, PE, flexible wire, stripped	5120.1346.0
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 10A	150 mm	AWG18	L, N, PE, flexible wire, stripped	5120.2046.0
CD, C20F, C22F, DC11, DC12, DD11, DD12, EC11, EC12, KD, KEA, KFA, KM, KMF, 2572, 4710, 4719, 4793, 4797, 4798, 5086, 5110, 5120, 5123, 5130, 5707, 6100-3, 6100-4, 6600-3, 6600-4, 6762, 6765	5120 APPLIANCE INLET FILTER 6A	150 mm	AWG18	L, N, PE, flexible wire, stripped	5120.3034.0
DC11.0001.001	DC11 POWER ENTRY MODUL 10A	150 mm	AWG18	L, N, PE, quick connect 4.8x0.8 mm, insulated	DC11.0001.003

The listed variants are often used.

For individual wire harness configurations select: test.schurter.ch/en/Components/Connectors/Wire-Harness-Request/