



GN03

Latex Examination Gloves

- ✓ **Latex**
- ✓ **Lightly powdered**
- ✓ **Natural**
- ✓ **Smooth**
- ✓ **XS-XL**
- ✓ **Ambidextrous**

Made of high quality natural rubber, GN03 gloves are designed to feel like a second skin. They offer a dependable and very comfortable and flexible solution to hand protection.

Attributes

- ✓ **Manufactured from** natural rubber latex
- ✓ **Low protein** minimising the risk of contamination and allergic reaction
- ✓ **Low in residual chemicals** to reduce the risk of contact dermatitis associated with these chemicals
- ✓ **Flexible material** for improved feel and fit reducing fatigue during extended wear
- ✓ **Beaded cuff** for added strength and easier donning
- ✓ **Lightly powdered** for easy donning and reduced perspiration
- ✓ **Smooth** finish

Regulatory Compliance

- ✓ Complies with:
 - Medical Devices Directives 93/42/EEC Class 1 (2007/47/EC)
 - EN455 parts 1, 2, 3 and 4: Medical Gloves for Single use
- ✓ Manufactured in accordance with:
 - European Personal Protective Equipment Directive 89/686/EEC
 - CE Category: Cat III (0086)
 - EN420: Protective gloves: General requirements
 - EN374-2 Protective gloves: Chemicals and Micro organisms penetration
 - EN374-3 Protective gloves: Chemicals and Micro organisms permeation
- ✓ Tested to:
 - AQL 1.5
 - EN388
 - ASTM F16771-7
 - Food approval EC1935/2004
- ✓ Powder content: max 10 mg /dm²
- ✓ Visually inspected for holes and minor defects
- ✓ Random samples are filled with 1L of water and examined for leaks
- ✓ Typical force at break: 6 Newtons
- ✓ Shelf life of 3 years



Warning: Contains natural rubber latex, which can cause allergic reactions, including anaphylactic responses.
Contains ZDBC and ZDEC chemicals, which can cause type IV skin irritation and contact dermatitis.

EN420	Level	EN374	Code
Dexterity	5	Sodium hydroxide 40%	K

Dimensions	XS	S	M	L	XL
Palm Width (mm)	≤ 80 ± 10	80 ± 10	95 ± 10	110 ± 10	≥ 110 ± 10
Length (mm)	Min 240				
Thickness (mm) palm	0.10 ± 0.02	0.10 ± 0.02	0.10 ± 0.02	0.10 ± 0.02	0.10 ± 0.02
Thickness (mm) finger	0.12 ± 0.02	0.12 ± 0.02	0.12 ± 0.02	0.12 ± 0.02	0.12 ± 0.02
Thickness (mm) cuff	0.07 ± 0.02	0.07 ± 0.02	0.07 ± 0.02	0.07 ± 0.02	0.07 ± 0.02

EN420: glove measurements are determined by taking into account the behaviour of the glove material and intended use



HPC
Healthline



0044 (0) 208 335 3636



0044 (0) 208 335 0300



sales@hpchealthline.co.uk



HPC Healthline Limited, Colwood House, 158 Garth Road, Morden, Surrey, SM4 4LZ, England



www.hpchealthline.co.uk



www.facebook.com/hpchealthline



#hpchealthline



GN03


Latex Examination Gloves

Packaging

Outer



Inner

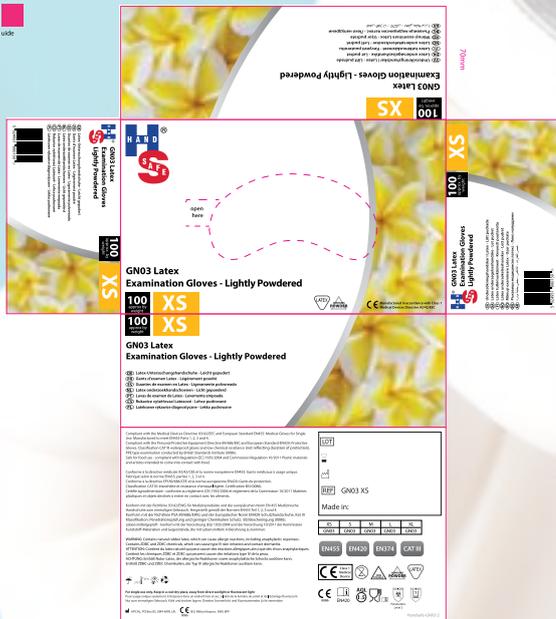

Dimensions

Inner: 200mm L x 120mm W x 70mm H

Outer: 360mm L x 245mm W x 210mm H

Size Colour Guide



Barcodes	Size	Inner Barcode	Outer Barcode
 5 024951 000150 >	XS	5024951000150	5024951002062
	S	5024951000167	5024951002079
	M	5024951000174	5024951002086
	L	5024951000181	5024951002093
	XL	5024951001201	5024951002109



Packing

Inner: 100 gloves per dispenser

Outer: 10 dispensers per case

Pallet: 84 cases per pallet

Symbols

Lot number	Compliant with the Medical Devices Directive	Compliant with the Personal Protective Equipment Directive	Temperature limitation
Date of manufacture	Non-sterile	EN420: Protective gloves: General requirements	Recyclable packaging
Use by	Acceptable quality level	EN374 - 2: Micro organism hazards	Keep dry
Manufacturer	Contains Latex	EN374 - 3: Chemical hazards	Keep away from direct sunlight and fluorescent lighting
Do not re-use	Contains powder	Food approved	

GN03/FEB2014



0044 (0) 208 335 3636

0044 (0) 208 335 0300

sales@hpchealthline.co.uk

HPC Healthline Limited, Colwood House, 158 Garth Road, Morden, Surrey, SM4 4LZ, England

www.hpchealthline.co.uk

www.facebook.com/hpchealthline

#hpchealthline