


170850 DFM-25-40-P-A-GF Guided drive - Series till 04-2015

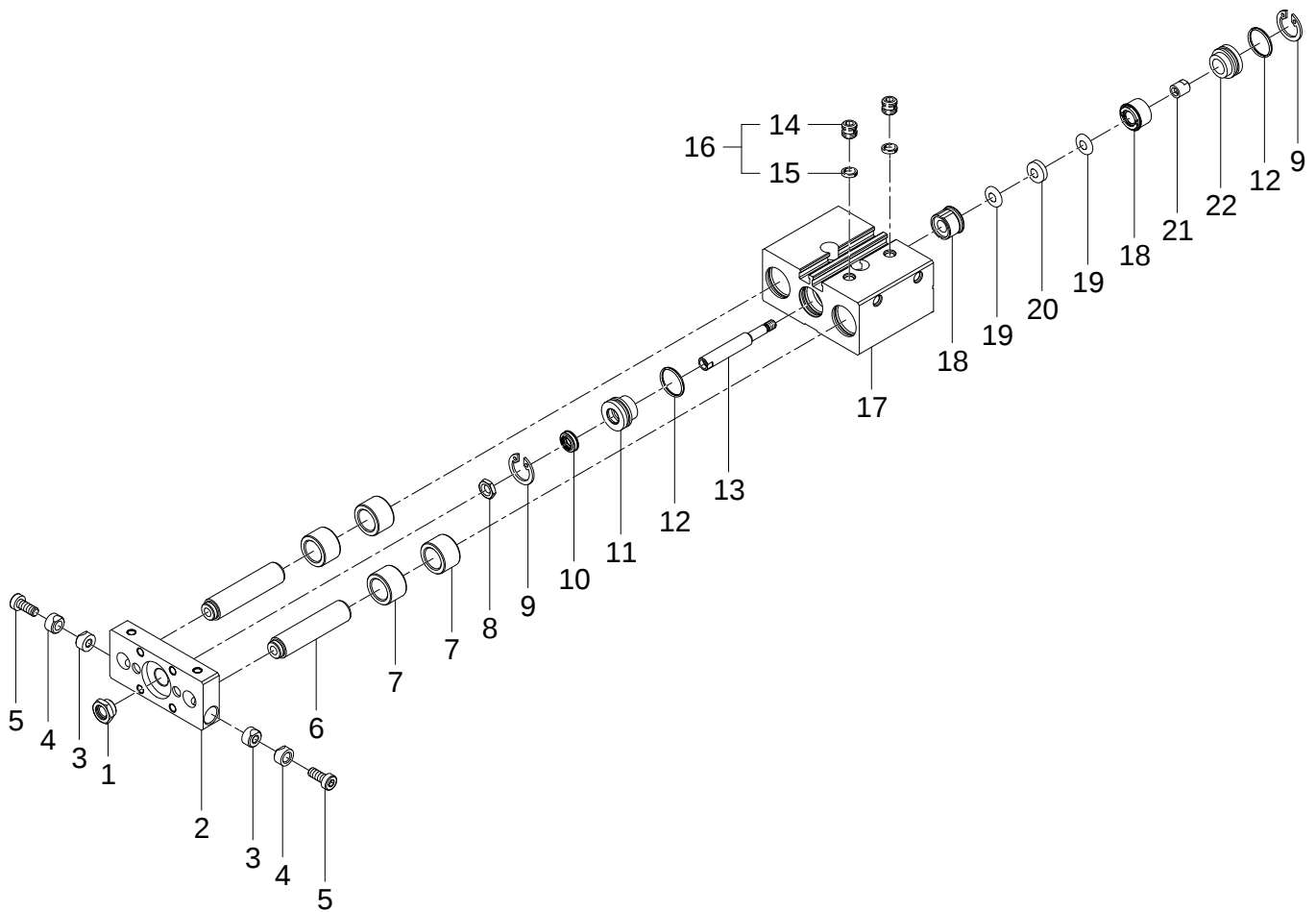

170850 DFM-25-40-P-A-GF Guided drive - Series till 04-2015

Pos.	Part no.	Type	Note	Qty.	Unit
A	383665	DFM- 25-PA Set of wearing parts	Spare parts: 10, 12, 15, 18 ▶ Replacing the wearing parts	1	PC
1	377739	M10X1.25 Collar nut	Use locking compound 8181256 CYBERBOND TM44 Tightening torque 28.3 Nm / 20.9 lbf ft	1	PC
2	671945	DFM-25-P-A End plate		1	PC
3	368080	M 5 Clamping piece		2	PC
4	368079	M 5 Clamping piece		2	PC
5	337166	DIN 6912-M5X16-8.8 Socket head screw	Use locking compound 8181256 CYBERBOND TM44 Tightening torque 6 Nm / 4.4 lbf ft	2	PC
6	368090	DFM- 25- 40PA-GF Guide rod		2	PC
7		DFM-25 Plain bearing	Not available	4	PC
8	387995	M10X1,25-1.0715 Hex nut	Tightening torque 28.3 Nm / 20.9 lbf ft	1	PC
9	201028	J-26 Retaining ring		2	PC
10		WIFC1-10X14X3,7-TPE-U Wiper seal	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	1	PC
11	713423	DFM - 25-PA Bearing cap		1	PC
12		B-23X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	2	PC
13	368104	KS D04 10 S0052.8 Piston rod		1	PC
14		G1/8A Plug screw	Not available separately, see position 16	1	PC
15		5,8X8,2X2 Sealing ring	Not available separately, see position 16+999	1	PC
16	116515	G1/8 Plug screw		1	PC
17		SNCS- 32 Swivel flange	Not available Lubricate with 684474 LUB-KC1 during assembly	1	PC
18		PEFC1-25-TPE-U Piston seal	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	2	PC
19	364616	6X23X1,8 Disc		2	PC
20	338249	23X6X2,5 Ring magnet		1	PC
21	338234	ADVU- 20/25 -PA Collar nut	Use locking compound 8181256 CYBERBOND TM44 Tightening torque 7 Nm / 5.2 lbf ft	1	PC
22		DFM - 25-PA End cap	Not available	1	PC