


Datasheet

500mA Axial FF Non-Resettable Wire Ended Fuse

RS Stock number 764-9457



Mechanical Dimensions: (mm)

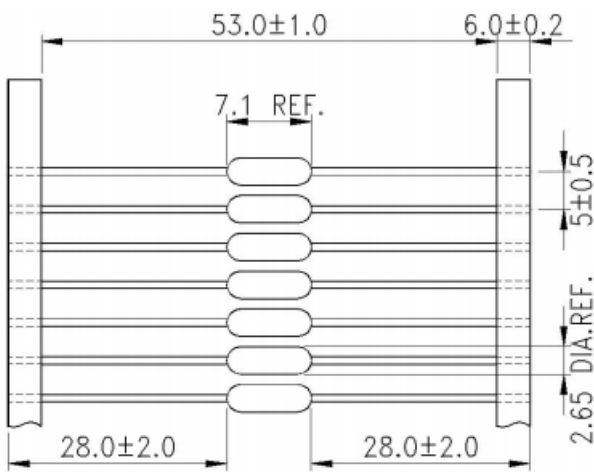

Specification

Approval

Recognized Component for Canada and U.S. 0.5A-5A
PSE 1A-5A

Electrical Characteristic

Rated Current	1 In	2 In
	MIN	MAX
0.5A-5A	4hr	120 sec

Physical Specification

Material

Encapsulated, Epoxy-Coated Body; Solder Coated
Copper Wire Leads.
Lead Wire: Diameter 0.65mm

Interrupting Rating

50 amperes at 125VAC / DC

Environmental Specification

Operating Temperature
-55°C to +125°C

Vibration

MIL-STD-202G, Method 201(10-55 Hz); Method 204,
Test Condition C (55-2000 Hz at 10G's Perk).

Moisture Resistance

MIL-STD-202G, Method 106.

