


# Datasheet

## Quick Splice Blue

RS Stock number [510-5346](#)

Drawing (mm):

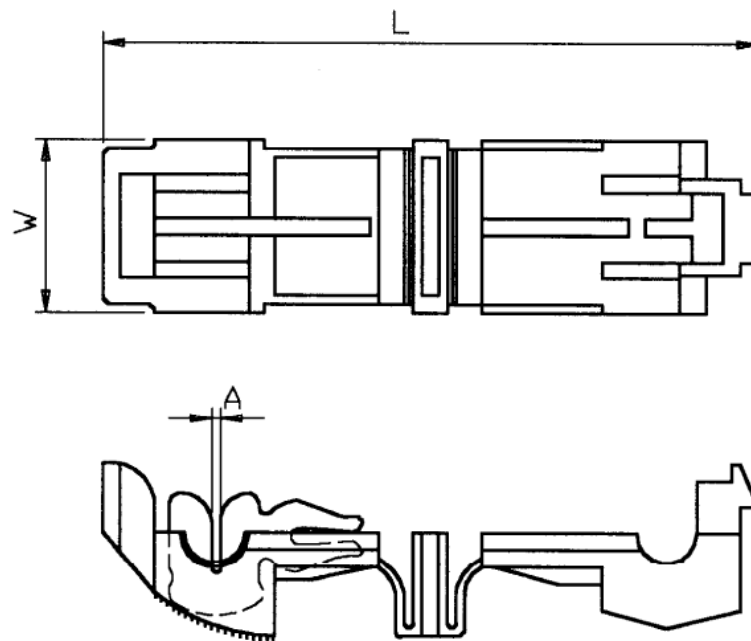

Tolerance	W $\pm 0.50$	L $\pm 1.00$	A $\pm 0.05$
Size (mm)	9.80	37.00	0.70

### Specifications:

Wire Range: 18-14 A.W.G (str & sol)  
 Electrical Rating: 105°C 600 Volts Max.  
 Electrical Current: 15 Amp