


Valve

VOFC-LT-M32C-MC-N14-FN

Part number: 8122933

FESTO

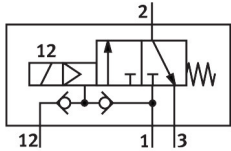

Data sheet

[PDF](#) General operating condition

Feature	Value
Standard nominal flow rate (standardised to DIN 1343)	703 l/min
Operating pressure	0.1 MPa ... 0.8 MPa
Operating pressure	1 bar ... 8 bar
Operating pressure	14.5 psi ... 116 psi
Degree of protection	IP65
Certificate issuing authority	TÜV 968/V 1251.00/24
Symbol	00992275
Safety function	Safe venting
Safety Integrity Level (SIL)	Up to SIL 3 High Demand mode To SIL 3 Low Demand mode
Note on operating pressure	0 - 0.8 MPa with ext. pilot air
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant