

IZTC, Controller IZTC41-P3

Datasheet

General series information


- IZTC40: Standard type / IZTC41: AC, Dual AC type.
- Controller separated from the bar.
- One controller can control a maximum of 4 ionizers.
- Monitor and operate bars which are installed in an inaccessible location.
- DIN rail mounting bracket available.
- Multiple alarms & functions.

Standard specifications


Model	41 (AC, Dual AC type)
Input, Output Specification	P (PNP)
Power Supply Cable Length	3 (3m)
Power Supply Cable Length (IO-Link)	None
Communication Cable Entry Direction/Length	None
DIN Rail Mounting Bracket	None
Maximum ambient temperature	40 °C
Minimum ambient temperature	0 °C
Approvals	CE
Power supply	24 VDC ±10%
Current consumption	1.4 A or less
Material	Cover: ABS, Aluminium, Switch: Silicone rubber
Ion generation method	Corona discharge type
Method of applying voltage	Dual AC
Applied voltage	±6000 V
Ambient humidity	35 to 80%RH (No condensation)
Offset voltage	Within ±30 V

Weight	0.420 Kg
--------	----------

Dimensions

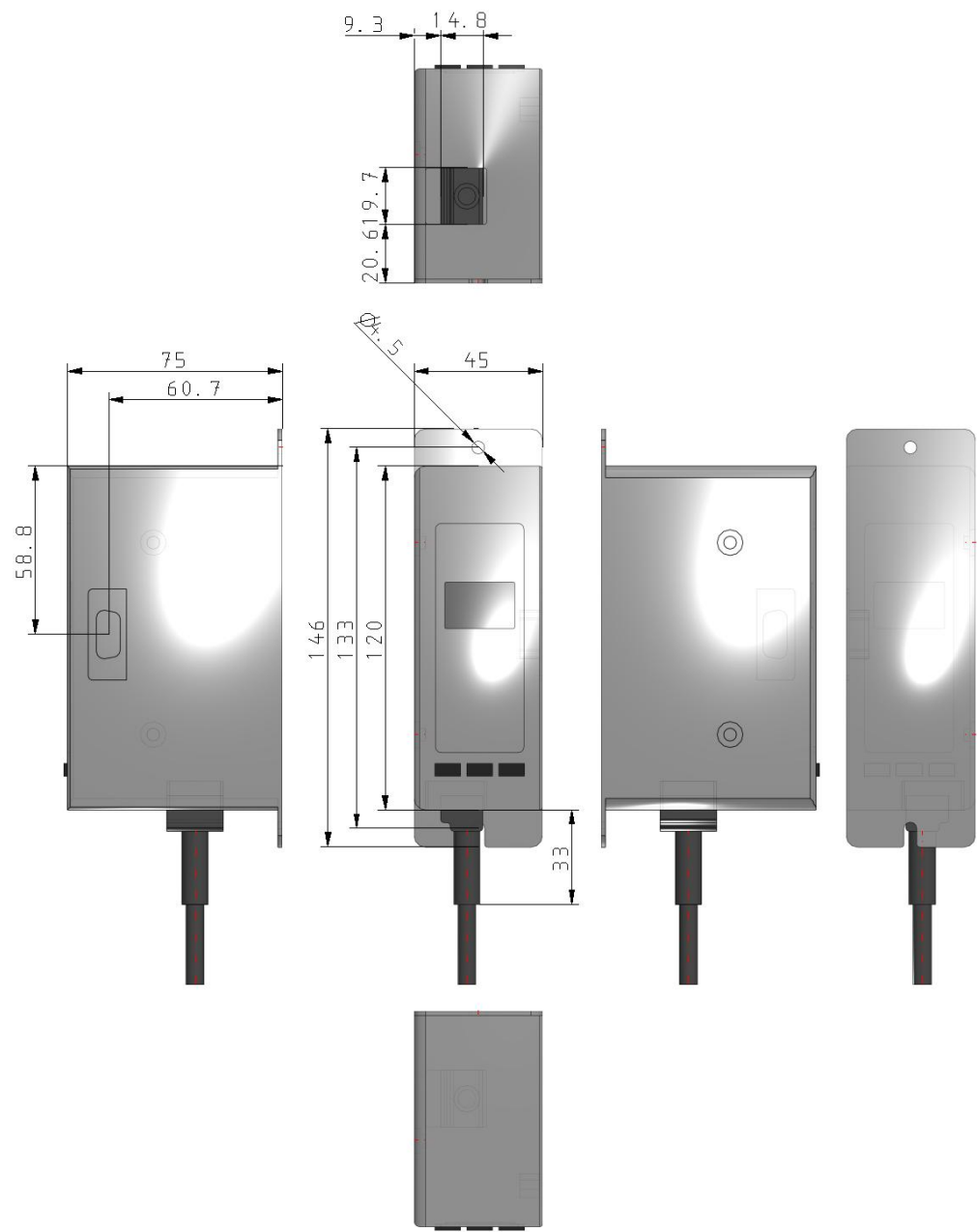

Constructions

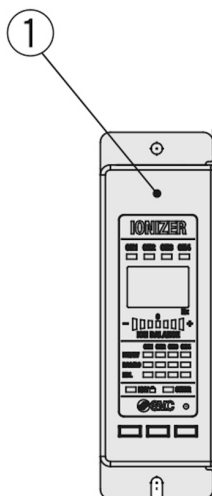

No.	Description
1	Controller

Additional information

Catalogue	IZT40-41-42-43-D_EU.pdf
Declaration of conformity	newDoC_Izt_TF122006EN.pdf newDoC_Izx_TFV0004EN.pdf
Installation manuals	IM_Izt_TF2Z267EN.pdf
Operation manuals	OM_Izt-L_OMZ0045EN-A.pdf OM_Izt41-42-L_OMT0049EN-E.pdf