 


Cast resin joint, Straight-through i, 4 x 150mm² to 4 x 240mm²,
L=700mm, 4 x 1640 ml, Polyurethane resin (PUR) black

Art.-No. 435-12107 | i-6 / SF-PUR-BK | 



- Two-part, impact-proof, transparent moulding shells
- Compact, optimized dimensions
- Standard cable diameters indicated on the shells
- Safe-Filling system (SF)
- Immediately ready for use
-
-




More products in this product group:

[Straight-through cable joints without connectors >](#)

Application	RELICON straight-through joints are provided with an integrated connector block and made for low-voltage electrical networks. They are suitable for jointing on polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables. Application: Connections in industrial buildings, power supply in the ground, outdoors and underwater.
Colour	Black (BK)
Content	Cast resin PUR 771 Two-chamber pouch, transparent Moulding shells, transparent SF-system and nozzle Protective gloves, emery cloth, installation instructions HelaTape vinyl electrical tape Spacer for max. 5 core cable (i-1 to i-4)
Material	Polyurethane resin (PUR)
No. of Wires	5
PART DESCRIPTION	i-6 / SF-PUR-BK
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON i-Line SF with PUR 771
Product Group	Straight-through cable joints without connectors
Type	i-6 / SF
Variant	Cast resin

Product Dimensions

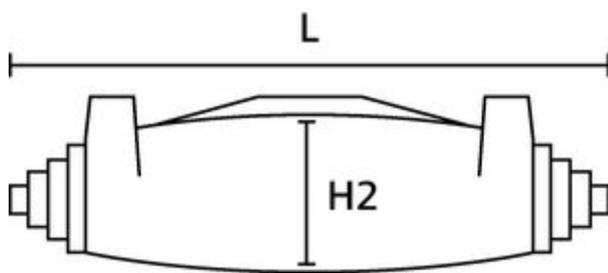

Conductor Size Range mm ²	150-240 mm ²
Height (H2)	128 mm
Length (L)	700 mm
Main Cable max	4 x 240 mm ²
Main Cable min	4 x 150 mm ²

ELV Compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +130 °C
ROHS compliant	Yes
Shelf Life	36 months
Specifications	
Voltage Range	0.6/1 kV

Logistics and Packaging

GTIN-13 / EAN	4031026627038
Packaging 3 - Height (m)	0.2 m
Packaging 3 - Length (m)	0.705 m
Packaging 3 - Qty	1
Packaging 3 - Type	carton
Packaging 3 - Volume (m ³)	0.0444 m ³
Packaging 3 - Weight (kg)	9.49 kg
Packaging 3 - Width (m)	0.315 m
Packaging 4 - Height (m)	1.145 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	15
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.099 m ³
Packaging 4 - Weight (kg)	163.35 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

More Information

