

Datasheet

RS Blue Hookup Wire, UL1213, 600 V RoHS Compliant, UL AWM STYLE 1213 105C, UL Style 1213

RS Stock number 813-3511



Product Description

Application:

general application and according to customer

 
Multi-construction

Single

Construction

Single	Silver Plated Copper
AWG	20
Construction	0.20±0.005x19
Stranded Dia.(mm)	0.96
Jacket	PTFE
Nom. Thickness (mm)	0.27
Jacket Dia.(mm)	1.5±0.1
Jacket Color	See Table 1

Marking(Color see table 1,3times/Per meters)(height:>-0.4mm)


Exxxxxx  AWM STYLE 1213 105C VW-1

20 AWG ROHS

PACKAGING

100m reel

Design

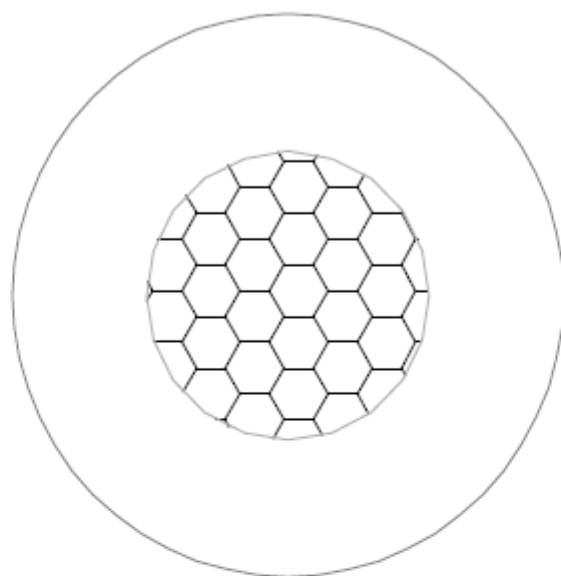

Electrical Characteristics

Max. Conductor DC Resistance at 20°C (Ω /Km)	35
Rated Temperature(°C)	-60 to 200C
Rated Voltage(V)	600
20°C Insulation Resistance(M Ω .KM)	> 200
UL	AWM 1213
Mil Spec reference	MIL-W-16878E
Flame Compliance	UL VW-1
Reference	BS 3G 210 Type B