

Freecom FHD-3 external hard drive



Intelligent hard drive with SYNC button and unique stackable & modular concept

Freecom FHD-3 7200rpm external hard drive


- Fast and silent external hard drive with One Button Data Synchronization
- Robust, heat absorbing aluminium enclosure for optimal cooling
- New storage concept provides easy extension with future Freecom peripherals
- Can be positioned horizontally and vertically, using the supplied footstand
- Add additional storage capacity to your computer in seconds!
- Easy to install, small form factor, ideal for both home and office use
- High quality, sleek design, only 175 x 144 x 44 mm, easy to take with you
- Including award-winning Acronis True Image software
- Including Freecom software suite (password protection, sync, secure & zip, autorun)
- Two years manufacturers warranty and unlimited free helpdesk support

Designed for:

- **Data storage;** use all your data like business information and digital photos, videos, MP3's and all other files directly from the drive
- **File sharing;** share all your important data between computers and networks
- **Backup;** protect your data against calamity, human errors and computer viruses
- **Archiving;** archive all your data and lock up the drive safely for extra data security
- **Modularity;** stack other modules (AV modules, Cardreader, Network module) on top of each other

The next generation in storage concepts!

Welcome to a new era in external hard drive storage! The Freecom FHD-3 offers a new, unprecedented concept of data storage. What seems like just another external hard drive is in fact the start of a new modular concept with the FHD-3 as the source. In the near future you will be able to find more Freecom products in the same look as the FHD-3, thereby making it possible to stack one unit on top of the other and creating a stack of multimedia products which could develop into the center of your personal data life. Think about adding an AV unit, enabling you to watch movies from your FHD-3 on your own TV. Or a Wireless adapter, enabling you to share the data on the FHD-3 in a wireless environment.... The possibilities are endless. Keep it simple!

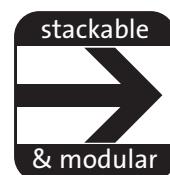

WWW.FREECOM.COM

Freecom
KEEP IT SIMPLE

Product specifications	Freecom FHD-3 7200rpm external hard drive
Storage capacity	160GB, 250GB, 400GB
Interface	USB 2.0 (& 1.1) & FireWire/i.LINK*, supports transfer rates of up to 480Mbit/s.
Performance	Average seek time: 8.5ms Track to track seek time: 0.8 ms Average latency: 4.17 ms Rotational Speed: 7200rpm
Data Transfer Speed	over USB 2.0 bus: up to 480Mbit/s over USB 1.1 bus: up to 12Mbit/s over FireWire bus: up to 400Mbit/s
Hard drive Buffer Size	8MB buffer
MTBF	50000 P.O.H.
Physical specifications	175 x 144 x 44 mm / weight 950 gr.
Environmental specifications	Operating Temperature 5° C to 55° C Storage Temperature -40° C to 65° C
System Requirements:	PC: Pentium-II 233MHz or higher, 64MB RAM, CD-ROM drive, Windows 98SE/Me/2000/XP, available USB 2.0/1.1 or FireWire/i.LINK* port. MAC: any MAC running OS 9.1 or higher.
Power Requirements	Voltage adapter 200 ~240VAC, automatic power ON-OFF function
Package includes:	<ul style="list-style-type: none"> FHD-3 external 7200rpm hard drive (Windows pre-formatted) Footstand for positioning the FHD-3 upright Universal Power Adapter (EU/UK/USA/JAP) USB connection cable (USB 2.0 & 1.1) FireWire/i.LINK connection cables** (1x 6 pin to 6 pin FireWire, 1x 6 pin FireWire to 4 pin i.LINK) Manual on CD, software suite on CD including Acronis True Image and Freecom Personal Media Suite Quick Install Guide 2 years manufacturers warranty and unlimited free helpdesk support
Optional	<ul style="list-style-type: none"> Freecom USB 2.0 PCI host controller, 2 ports

* depends on model, please check product label/sticker on retailbox

** only with the U&F (USB-2 & FireWire) versions

	160GB USB 2.0	250GB USB 2.0	160GB U&F	250GB U&F	400GB U&F	FA1 2 ports PCI hostcontroller
Art. No. EU/UK	22617	22972	22975	22976	22977	17789
EAN code EU/UK	4021801226174	4021801229724	402180129755	4021801229762	4021801229779	4021801177896
Color	anthracite aluminium					

