


## Datasheet

# Fuse Disconnect Terminal

RS Stock number 872-5634

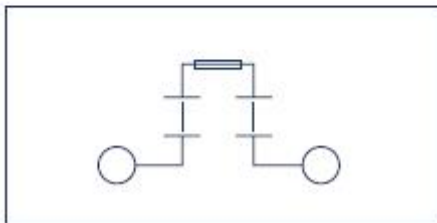

Fuse-disconnect terminal  
2 connections/hinged lever

## Features

- Foot can be snapped on TS 32 and TS 35 DIN rails
- Housing made from polyamide 6.6 UL 94-V2

## Specifications:

Rated wire cross-section, mm<sup>2</sup> | AWG: 10 | 22-12

Rated impulse voltage, kV | Contamination degree: 8 | 3

Max. power loss, W: 1.6

Plug gauge acc. to EN 60 947-1 | Flamm. class acc. to UL 94: A4 | V2

## Connection data

Single wire (solid) / Stranded mm<sup>2</sup>: 0.2-10 | -

Stranded/stranded (w/ferrules acc. to DIN 46 228/1) mm<sup>2</sup>: 0.2-10 | 0.2-10

Contact wire range, mm<sup>2</sup>: 0.2-10

Stripping length, mm: 12

Torque, Nm | Screw: 1.2-2.0 | Slotted M 4

Fuse size: 6.3 x 32/6.3 x 25