

Technical Information: Alkaline Manganese Batteries

LR14PS

■ Appearance



The data in this document are for descriptive purpose only and are not intended to make or imply any guarantee or warranty


■ Technical data & Discharging time

Type designation	LR14PS		
Nominal voltage	1.5V		
Weight	65g		
Outer dimension	Height	49.6mm	
	Diameter	25.6mm	
Typical duration @20°C	400mA 2h/day (0.9V)	Portable stereo	12.5h
	3.9Ω 4h/day (0.8V)	Toy	22h
	3.9Ω 4min ON/11min OFF 8h/day (0.9V)	Portable lighting	1200min


Note) Value in parenthesis is end point voltage of each discharge.

■ Typical discharging curve

Portable stereo[400mA 2h/day]

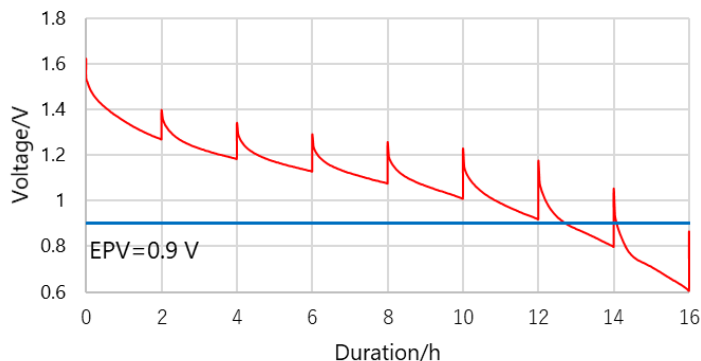

Toy[3.9Ω 1h/day]

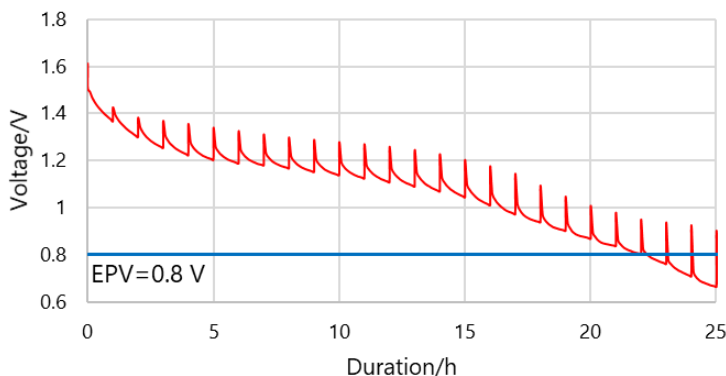

Portable lighting[3.9Ω 4min ON/11min OFF 8h/day]

