



**THE GERMAN  
WORKSPACE  
BRAND** 

## ICY BOX IB-RD3720-CU3

RAID system for 2-bay 2.5"/3.5" SATA  
HDD/SSD with RAID mode switches


### Key features

- Supports 2x 2.5"/3.5" HDD/SSD
- Host connection USB 3.2 Gen 1 Type-C® with up to 5 Gbps
- RAID mode DIP switch for RAID 0/1/SINGLE/LARGE
- Supports SATA III, backwards compatible with SATA II
- Built-in 50x50 mm fan for optimal heat dissipation
- LED indicator for power, read & write (blue), error (red)
- AC 100-240 V/12 V/4 A power adapter included



### Packing content

1x IB-RD3720-CU3, 1x USB Type-C® to Type-C®/A cable (100 cm), 1x Screwdriver, 10x Screw, 1x Tool for RAID switch, 1x 12 V/4 A power adapter, 1x Manual

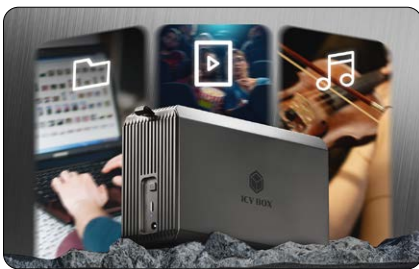

### Double the bays, double the choice

With room for two drives, the IB-RD3720-CU3 is designed to work with both 2.5" and 3.5" HDDs or SSDs, giving you the freedom to mix and match based on your storage needs. Whether you prefer the compact size of 2.5" drives or the larger capacity of 3.5", installation is straightforward and convenient.



### Connect fast, work faster

With its USB 3.2 Gen 1 Type-C® connection, this RAID system keeps data moving at speeds of up to 5 Gbps. That means large video files, photo libraries, or project backups transfer quickly without long waits. USB Type-C® is compatible with a wide range of modern notebooks, desktops, and devices, so you spend less time worrying about cables and enjoy more time focusing on your work or entertainment.



### Switch it your way

The built-in DIP switch makes it simple to choose how your storage works for you. With just a flick, you can select between four modes: RAID 0 for faster access, RAID 1 for reliable backup, SINGLE for independent drives, or LARGE to combine capacity into one big volume. There's no complicated setup and you can adapt the system to different projects, balancing performance and protection depending on what matters most.



**THE GERMAN  
WORKSPACE  
BRAND** 

## ICY BOX **IB-RD3720-CU3** RAID system for 2-bay 2.5"/3.5" SATA HDD/SSD with RAID mode switches

### General data

Model	IB-RD3720-CU3
Article no.	61191
EAN code	4250078175254
Colour	Black
Material	Aluminum
Interface to host computer	USB 3.2 Gen 1 Type-C®
Length of cable	100 cm
Transfer rate	Up to 5 Gbps
UASP support	-
Plug & Play	Yes
LED	Power
ON/OFF button	Yes
Chipset	JMS561

### Drive data

Drive size	2.5"/3.5"
Drive height	-
Drive interface	SATA II, SATA III
Drive capacity	Up to 30 TB
Supported M.2 card keys	-
Space required	-
Clone function	-
HotSwap	Yes
Write protection	-

### RAID data

RAID level	RAID 0/1/SINGLE/LARGE
Auto rebuilding	-
Alarm	-

### Additional features

Additional interfaces	-
Display	-
Control buttons	Yes
Lock	-
Kensington Lock	-
Degree of protection	-
Cooling	50x50 mm fan
Fan volume	-

### Power

Power supply	12 V/4 A
Plug dimension	DC plug, Ø5.5xØ2.1xL10 mm, DC cable 1.2 m

### Host system

Relative humidity	5% ~ 90%
Operating temperature	0°C ~ 40°C
Operating system	Windows®, macOS®, Linux®
System requirements	One free USB Type-C® or Type-A port on your computer

### Logistical data

Packing unit	8 pcs. / carton
Total weight	10.16 kg
Gross weight (with packing)	1.16 kg
Net weight	0.786 kg
Dimension/carton	385x370x320 mm
Dimension (with packing)	300x175x100 mm
Dimension of article	200x65x117 mm
Country of origin	China



THE GERMAN  
WORKSPACE  
BRAND 

## Best combined with



### **IB-2924MSCL-C31**

Clone & Docking Station for SATA & M.2 HDDs/SSDs

[About the product](#)

### **IB-127CL-U3**

Docking & Klonstation for 2x HDD/SSD

[About the product](#)

