


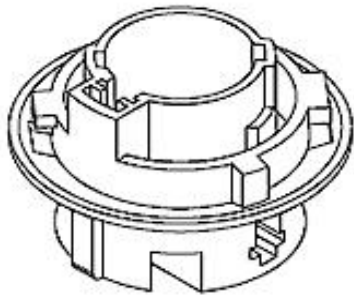

**Part Number :** [355330205](#)  
**Product Description :** PT Bulb Socket Single  
Housing Assembly, Type A, P21W, Unsealed, Gray  
**Series Number :** 35533  
**Status :** Obsolete  
**Product Category :** Sockets



## Documents & Resources

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

## Part Details

### General

Status	Obsolete
Category	Sockets
Series	35533
Description	PT Bulb Socket Single Housing Assembly, Type A, P21W, Unsealed, Gray
Comments	A-Type
Component Type	Socket
Product Name	PT Bulb Socket
UPC	756054202852

### Electrical

Current - Maximum per Contact	7.0A
Voltage - Maximum	12V

### Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Gray
Durability (mating cycles max)	50
Entry Angle	Vertical
Keying to Mating Part	None
Material - Metal	Phosphor Bronze
Material - Resin	Nylon
Net Weight	5.520/g
Packaging Type	Bag
PCB Locator	No
PCB Retention	N/A
Pitch - Mating Interface	N/A
Temperature Range - Operating	-40° to +85°C
Termination Interface Style	Through Hole

---

### Mates With / Use With

**Mates with Part(s)**

Description	Part Number
Mates With	Bayonet Base Bulb

**Use with Part(s)**

Description	Part Number
Contact Terminals for PT Bulb Socket	<u>35438</u>
2.00mm Bulb-Socket Earth Terminals	<u>35439</u>