



tesa® Ultra Power Lock Strips

Product Information

BNR 55234

Product Description

tesa® Ultra Power Lock Strips are a robust alternative to hook and loop tapes. Featuring exceptionally strong adhesive, it is the most reliable hook and loop tape offered by tesa® – for both permanent and temporary fixes, indoors and outdoors.

Product Features

- Versatile: The hook and loop strips are suitable for a wide range of indoor and outdoor tasks
- Strong adhesive power: The hook and loop strips withstand loads of up to 4 kg/package
- Unique mushroom lock: It is the strongest hook and loop tape in the tesa® range
- Powerful, dual-sided adhesion: An adhesive layer on the back of the tape offers an extra strong hold
- Resilient: UV-resistant, weatherproof and withstands temperatures ranging from -30 to +90°C
- Practical: The hook and loop straps make a clicking sound to signal a secure connection
- Flexible: The strips stay securely in place, even when applied to the ceiling
- Reusable: The hook and loop fastener can be opened and closed as frequently as needed
- Ceiling application: Max. weight 0.5 kg; Other applications: Max. 4 kg, with a height of up to 2.7 m

Application Fields


- Versatile: The hook and loop strips are suitable for a wide range of indoor and outdoor tasks
- Strong adhesive power: The hook and loop strips withstand loads of up to 4 kg/package
- Unique mushroom lock: It is the strongest hook and loop tape in the tesa® range
- Powerful, dual-sided adhesion: An adhesive layer on the back of the tape offers an extra strong hold
- Resilient: UV-resistant, weatherproof and withstands temperatures ranging from -30 to +90°C
- Practical: The hook and loop straps make a clicking sound to signal a secure connection
- Flexible: The strips stay securely in place, even when applied to the ceiling
- Reusable: The hook and loop fastener can be opened and closed as frequently as needed
- Ceiling application: Max. weight 0.5 kg; Other applications: Max. 4 kg, with a height of up to 2.7 m

Technical Information (average values)

The values in this section should be considered representative or typical only and should not be used for specification purposes.

Product Construction

- | | | | |
|--------------------|---------|-----------------------|---------|
| • Backing material | PE | • Total thickness | 4600 µm |
| • Type of adhesive | acrylic | • Holding power up to | 4 Kg |

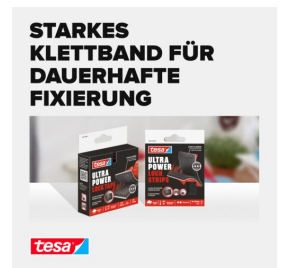



tesa® Ultra Power Lock Strips

Product Information

Properties/Performance Values

• Adhesive strength	Very high adhesion	• Residue free removal	no
• Application temperature from	-30 °C	• Solvent free	no
• Application temperature to	90 °C	• Suitable surfaces	Lacquered wood, Tiles, Most plastics, Glass, Acrylic glass, Metal, Steel
• Applicationfield	Office, Garage, Car, Home		
• Area of use	In- and Outdoor	• Temperature resistance	yes
• Material	PP (polypropylene)	• UV-resistant	yes

Disclaimer

tesa® products prove their impressive quality day in, day out in demanding conditions and are regularly subjected to strict controls. All information and recommendations are provided to the best of our knowledge on the basis of our practical experience. Nevertheless tesa SE can make no warranties, express or implied, including, but not limited to any implied warranty of merchantability or fitness for a particular purpose. Therefore, the user is responsible for determining whether the tesa® product is fit for a particular purpose and suitable for the user's method of application. If you are in any doubt, our technical support staff will be glad to support you.

For latest information on this product please visit <http://l.tesa.com/?cp=NaN>