


FEATURES

- Clear LCD display
- Stainless Steel construction
- Origin setting
- Switchable On/Off
- Thumbwheel for fine adjustment
- Knurled locking screw
- Supplied with battery

RS PRO 200mm Digital calliper 0.0005 in, 0.01 mm, Metric & Imperial

RS Stock No.: 841-2511

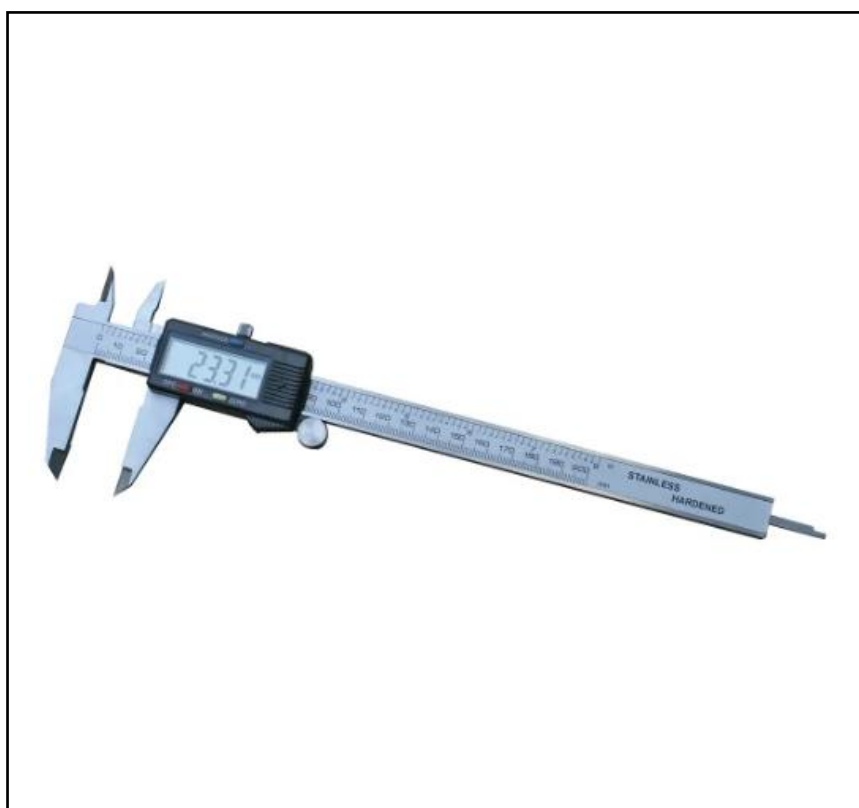

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS Pro Digital Callipers use linear encoders to measure internal and external distances. This is then shown on a digital display which is simple to use and easy to read. This handy tool is available with metric and imperial conversions so you can accurately measure objects with ease

General Specifications

Caliper Type	Digital
Imperial or Metric	Both
Display Type	Digital
Accuracy	0.03mm
Resolution	0.0005 in, 0.01 mm
Repeatability	0.01mm / 0.0005 in
Thumb roller	Yes
Button function	on/off, zero, mm/inch
Data Output	No
Applications	for use in laboratories, electrical and electronic servicing, and maintenance, mechanical and automotive applications

Electrical Specifications

Power	1 x Silver oxide battery SR44 - 1.55v
Battery	Yes
Battery type	SR44

Mechanical Specifications

Capacity	200mm
External Jaw Length	50mm
Internal Jaw Length	20mm
Accuracy External Jaws	±0.02mm
Accuracy Internal Jaws & Depth Rod	±0.02mm

Operation Environment Specifications

Operating temperature	5 - 40°C
Relative humidity	Maximum 80%



