

# EKH 30-G



Sample image

**Order symbol :** EKH 30-G

**Product nr :** 3730147



**Description :** Cover, PC

**Remarks :** Grey

**EAN :** 6418074000200

**El. number :**

- Finland : 3420151
- Denmark : 8212007026
- Sweden : 2537852

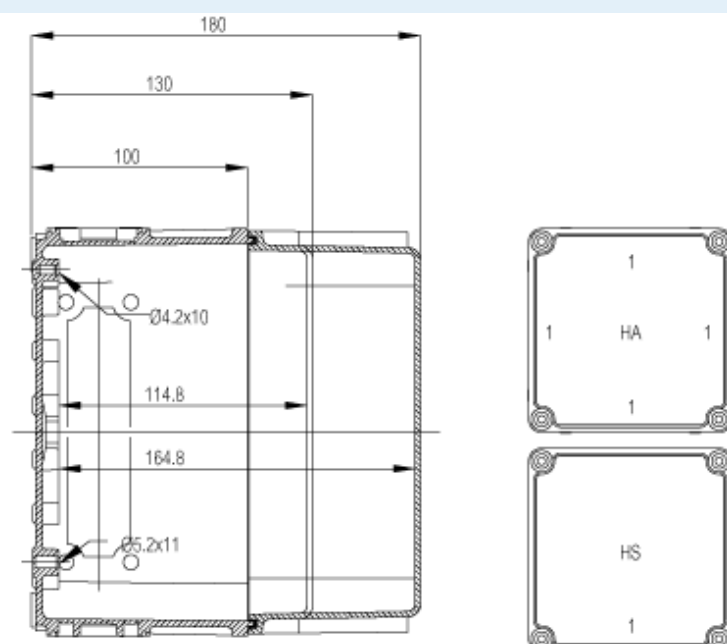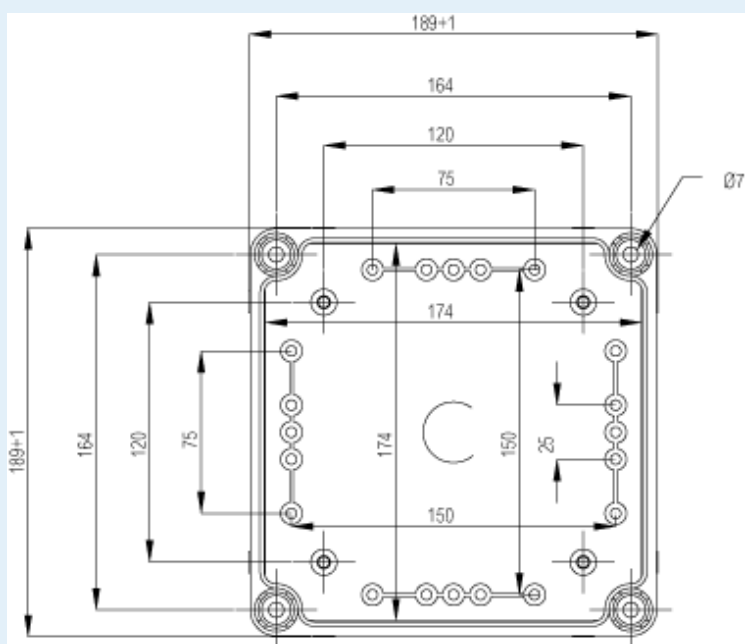

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 190    | 190   | 30    |
| inch :       | 7.48   | 7.48  | 1.18  |

## Materials :

|                   |                      |
|-------------------|----------------------|
| Material :        | Polycarbonate        |
| Cover colour :    | RAL 7035 -light grey |
| Gasket material : | Polyurethane         |

## Accessories :

|              |                                                           |
|--------------|-----------------------------------------------------------|
| EKHVT        | Mounting plate, for enclosures:<br>(158 x 158 x 1.5)      |
| EKV 12       | DIN-35 Mounting rail, for enclosures:<br>(160 x 35 x 7)   |
| MPI EKH 1919 | Multiperforated plastic mounting plate<br>(167 x 167 x 4) |

## Ratings :

|                         |                   |
|-------------------------|-------------------|
| electrical_insulation : | Totally insulated |
|-------------------------|-------------------|

**Temperatures :**

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

UV resistance : UL 746C

Flammability Rating : UL 94 V0

Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

SGSFIMKO\_EK